





Technical data

51317

One direction thrust ball bearings

VISUAL (S)

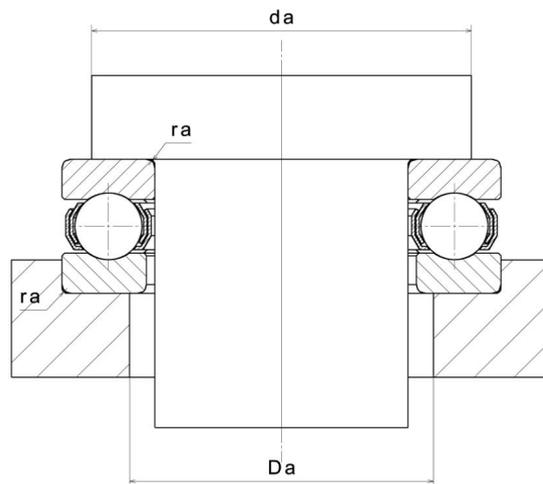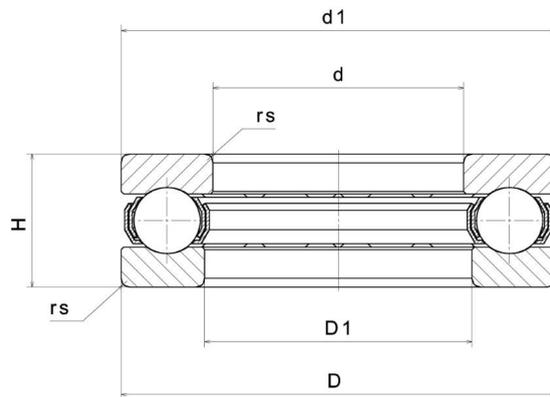

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	85 mm
D - External diameter	150 mm
T - Thrust bearing height	49 mm
rs - Min fillet radius	1,5 mm
Mass	3,52 kg

PRODUCT PERFORMANCE

Ca - Dynamic axial load rating	206000000 mN
C0a - Static axial load rating	490000000 mN
Cua - Limit axial load rating	20300000 mN
N lim - Oil lubrication limit speed	9600 °/s
N lim - Grease lubrication limit speed	6600 °/s
Tmin - Min operating temperature	233,15 °K
Tmax - Max operating temperature	393,15 °K

ABUTMENT

Da max - Max shoulder diameter OR	111 mm
da min - Min shoulder diameter IR	124 mm

