


PB05

PanelMaster Power/Relay PCB

Features & Benefits

One year warranty only.

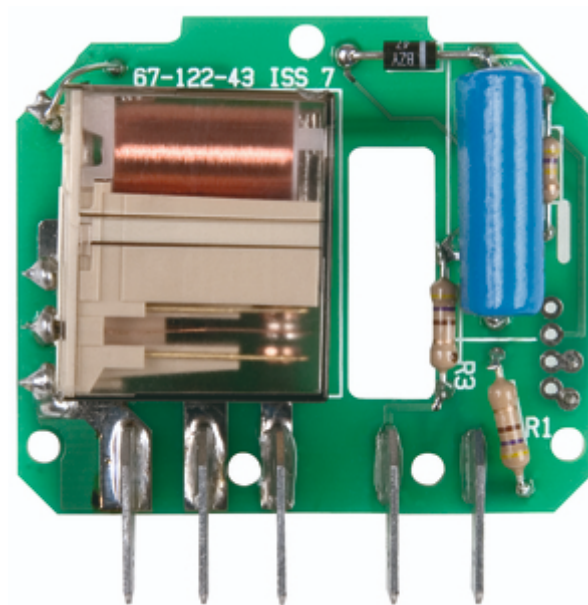

Technical Data

Operating Voltage	230V AC
Frequency	50Hz
Installation Type	OEM
Operating Temperature	-10°C to 40°C
Switch type	Single Pole
Voltage Free Contacts	Normally Open, Normally Closed (Changeover)
Number of Channels	1
Switch rating	16A Resistive, 6A Inductive, 10A Halogen, 500W Fluorescent, 1HP Motor
Cable Entry(s)	Bottom Entry (Spade Connector)

General

Data sheet

PB05

Time / OEM Modules

Weight (g)	35
Height (mm)	55
Width (mm)	55
Depth (mm)	18
Body Construction	Contacts (Silver Cadmium Dioxide), Board (Soldermask, Copper, Laminate)
EAN Number	5012483006481
Guarantee Period	1 Year