


Vertical busbar support cascaded, 2 x 30 x 10 mm

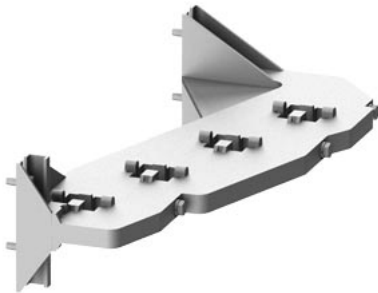

Model	
product brand name	SIVACON S4
product designation	Vertical busbar holder
design of the product	cascaded
General technical data	
number of poles	4
Main circuit	
operational current rated value maximum	1 190 A
type of connectable conductor cross-sections for copper conductor stranded	30x10
Mechanical Design	
height	165 mm
width	375 mm
depth	100 mm
busbar center-to-center spacing	80 mm
net weight	9 760 g
Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Miscellaneous](#)

other	Environment
Confirmation	Environmental Con- firmations
	Environmental Con- firmations

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ4000-0BA32>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ4000-0BA32>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ4000-0BA32

last modified:

4/4/2025 

