


# Triple-Display TV Wall Mount - Menu Board Mount - Landscape

Product ID: FPWMNB

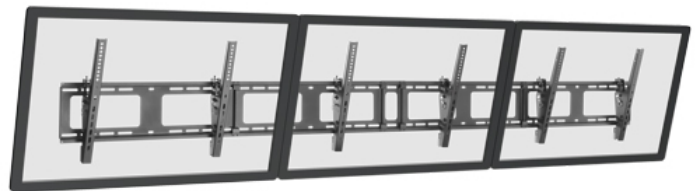

Create a perfectly aligned menu board with this triple-display TV wall mount for 40" to 50" displays. The modular wall-mounting system is easy to set up. Adjust the tilt for all three displays at the same time, and fine-tune the screen level with ease.



## Enhance Customer Sales

Digital menu boards are a great way to increase customer sales, promote new offerings, and inform customers at the point of sale. Ideal for restaurants, retail stores and many other businesses, this professional-grade menu board mount supports three 40" to 50" VESA mount TVs in landscape position. It supports a weight capacity of 110 lb. (50 kg) per display, and is compatible with VESA 200x200, 300x200, 300x300, 400x200, 400x300, 400x400, and 600x400.

## **Adjust Your Display with Ease**

For optimum viewing, you can adjust the tilt of all three displays to the same angle simultaneously, without using tools. The multi-screen mount has five fixed tilt settings: 0°/-5°/-10°/-15°/-20°.

## **Align the Screen Level of All Monitors**

To ensure precise alignment of all three TVs, you can fine-tune the level of the displays +3° to -3° using the micro height adjustment feature.

## **Durable Steel Construction**

With its heavy-duty steel construction, the triple-monitor wall bracket provides durable performance.

## **Fast and Easy Installation**

Save time on setup. The hook-and-mount design of the triple-display wall mount makes installation fast and easy.

FPWMNB is backed by a StarTech.com 5-year warranty and free lifetime technical support.

### Certifications, Reports and Compatibility



### Applications

- Ideal for digital menu boards in restaurants and retail stores
- Create digital signage in customer-facing areas in business lobbies, airports and hospitality centers
- Communicate with visitors in schools, health care centers and other institutional settings

### Features

- Create a digital menu board, mounting three 40" to 50" TVs in landscape position
- Tilt all displays to the same angle easily, with five fixed-tilt settings: 0°/-5°/-10°/-15°/-20°
- Align your displays with micro height adjustment, fine-tuning the screen level +3° to -3°
- 3.0" (76 mm) profile to wall, and fast and easy installation
- Steel mount supports VESA 200x200, 300x200, 300x300, 400x200, 400x300, 400x400, 600x400, and up to 110 lb. (50 kg) weight per display

<b>Hardware</b>	Warranty	5 Years
	Cable Management	No
	VESA Hole Pattern(s)	200x200 mm
		300x200 mm
		300x300 mm
		400x200 mm
		400x300 mm
		400x400 mm
600x400 mm		
Wallmountable	Yes	
<b>Performance</b>	Anti-theft	No
	Display Tilt	0 / -5 / -10° / -15° / -20°
	Fits Curved Display	No
	Maximum Display Size	50"
	Minimum Display Size	40"
	Screen Level Adjustment	+3° to -3°
	Video Wall	No
	Weight Capacity (Per Display)	110.5 lb [50 kg]
<b>Physical Characteristics</b>	Color	Black
	Material	Steel
	Product Height	8.9 in [22.5 cm]
	Product Length	9.5 ft [2.9 m]
	Product Width	3.1 in [78 mm]
	Weight of Product	31.5 lb [14.3 kg]
	<b>Packaging Information</b>	Package Height
Package Length		29.1 in [74 cm]
Package Width		9.8 in [25 cm]
Shipping (Package) Weight		35.4 lb [16 kg]
<b>What's in the Box</b>	Included in Package	4 - Wall Plates
		1 - Small Wall Plate

- 6 - Adapter Brackets
- 8 - Wall Plate Clamps
- 6 - Safety Pins
- 16 - M4 x 6 mm Screws
- 12 - M5 x 14 mm Screws
- 12 - M6 x 14 mm Screws
- 12 - M6 x 30 mm Screws
- 12 - M8 x 30 mm Screws
- 12 - M8 x 50 mm Screws
- 12 - Plate Washers
- 24 - Small Spacers
- 24 - Large Spacers
- 18 - ST6.3 x 55 mm Screws
- 18 - Concrete Anchors
- 18 - D6 Washers
- 1 - 5 mm Hex Key
- 1 - User Manual

---

Product appearance and specifications are subject to change without notice.