


# 19" fan units

## Standard types

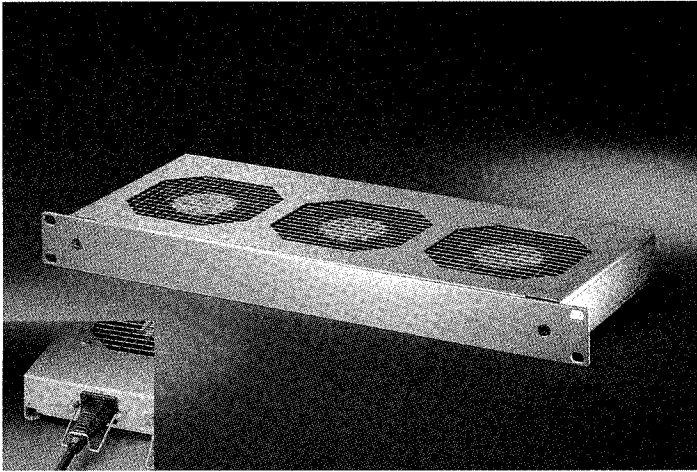


### Ordering 19" fan unit 1 U without illuminated switch

- High airflow
- Touch protection to EN 292 parts 1 and 2
- Can be assembled to subracks
- Mechanical safety device for power lead



### Dimensions

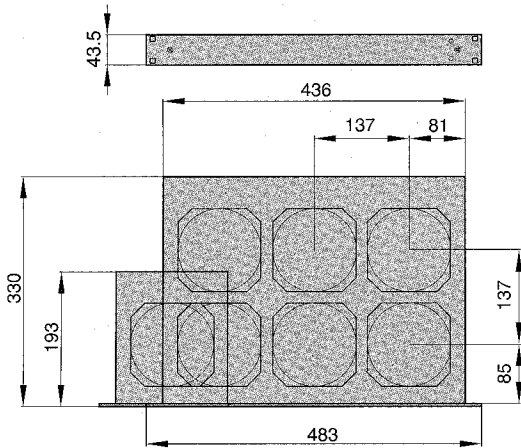

A3532

### Delivery comprises

 

Item	Qty	Description	Material	Finish	Notes
1	1	Front panel	Al 3 mm	anodized	
2	1	Housing	St 1 mm	Al Zn	
3	1	Grille			
4	Depends on version	Fan			See technical data
5	1	Industrial plug		black	Mains/line input
6	1	Safety device	St	zinc-plated	Mechanical safety device for power lead

Delivery: items 1 - 5 assembled

### Technical data for the individual fans

	Unit	230		240		115		24
Voltage	V							
Frequency	Hz	50	60	50	60	50	60	DC
Air capacity	m <sup>3</sup> /h	162	192	162	192	162	192	184
Suppression	dB (A)	37	41	37	41	37	41	42
Max. static pressure	Pa	73	88	73	88	73	88	68
Max. ambient temperature	°C	+70		+70		+70		+70
Power consumption	W	15	14	15	14	15	14	8

19" fan units

19" fan unit 1 U without switch			
Number of fans		3	6
Operating voltage	230 V 50 ... 60 Hz	10713-100	10713-104
	240 V 50 Hz	10713-101	10713-105
	115 V 50 ... 60 Hz	10713-102	10713-106
	24 V <sup>1)</sup> DC	10713-103	10713-107
Mains/line connection lead 2.5 m - for AC fans	SCHUKO/UTE: 60103-131	BS: 60103-137	I.E.C.: 60103-141
Subrack/fan unit adaptor	21101-104		

<sup>1)</sup> The 1.5 m connection cable is supplied with units operating at 24 V DC