

PRODUCT DETAILS

ARTICLE: [36639FD](#)



WHEEL AS 100X40/40 ROLLER BRGS. BOLT HOLE FORK M22/50 HOLE 14

Wheel series AS

Wheels with cast soft polyurethane coating 87 Sh.A on polyamide 6 center.
Wheel fitted with standard roller bearing.

Castor series M22


M22 series, Medium-light pressed steel fork assemblies; swivel version has double ball raceways. Zincplated.

Single bolt hole fixing for bolt diam. 12-14 mm.



Technical data

Wheel diameter	D	100 mm
Tyre width	E	40,0 mm
Bore diameter	d	15 mm
Weight article		0,870 kg
Hub width	L	40 mm
Overall height	H	129 mm
Fixing bolt diameter	g	M12-14
Offset	F	46 mm
Fork width	U	50 mm
Load Capacity		200 kg

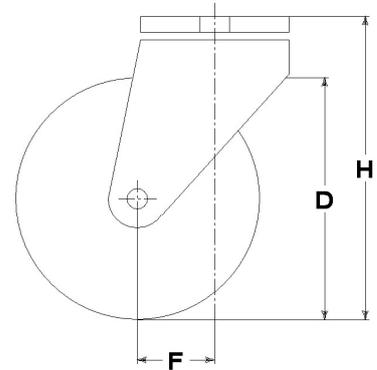

Related Articles

Spare part wheel: [35058](#)

Version with trailing brake: [36639FRFD](#)

GENERAL INFORMATION / RECOMMENDATIONS AND WARNINGS

The cited text and the complete catalogue in their most up-dated versions are available in the OEM's website page www.lagspa.it/downloads. The dimensions, descriptions, specifications and illustrations herein are indicative and subject to variations without notice. The fact that products are illustrated herein does not necessarily imply they are available from stock nor does it place us under any obligation to supply them.

Tests carried out refer to the original products with original accessories: the replacement of one of the components with others of different manufacture might prevent the same results from being achieved and will automatically invalidate any guarantee. Please contact our technical service concerning any special application.