

Mini CMEL



Technical specifications



Suitable for the following cable types



Non-armoured cable

Cable with insulated conductors, with no metallic layer of mechanical protection.

Certifications

EN 62444

Continuous operating temperature

-20 °C to + 100 °C

ISO (metric) threadforms

EN 60423 and EN 62444

Material


Body and cap: nickel-plated brass

Sealing ring: nitrile rubber

O-ring: nitrile rubber

Perfectly adapted to industrial environments

- The Mini CMEL ensures the tightness on the cable outer sheath
- Provided with an integrated o-ring
- IP66

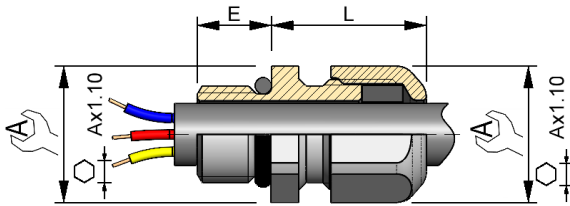

* For 'across corners' dimensions, multiply 'across flats' dimensions by 1.1

Description

Our range of metallic industrial cable glands Mini CMEL allows the connection of very small diameter non-armoured cables.

Accommodating a nitrile rubber sealing ring, an IP66 as well as a perfect tensile strength are achieved.

Mini CMEL cable glands are provided with ISO 8 and ISO 10 threads.



Powering Business Worldwide

Ordering codes

Mini C MEL - ISO thread

ISO THREAD	MIN CABLE DIAMETER	MAX	ORDER UNIT	CATALOG NUMBER
8 x 1.25	3.0	5.3	20	CAP170804
10 x 1.5	3.5	6.5	20	CAP171004

All dimensions in mm.

