 


Cast resin joint, Straight-through i, 5 x 1.5mm² to 5 x 16mm²,
L=276mm, 400 ml, Polyurethane resin (PUR) black
Art.-No. 435-12110 | i-2 Premium / SF-PUR-BK | 




- Two-part, impact-proof, transparent moulding shells
- Compact, optimized dimensions
- Standard cable diameters indicated on the shells
- Safe-Filling system (SF)
- Immediately ready for use
- Longitudinally and transversely watertight
- Joint can be submerged directly after casting
-
-



More products in this product group:
[Straight-through cable joints with connectors >](#)

Application	RELICON Premium straight-through joints are provided with an integrated connector block and made for low-voltage electrical networks. They are suitable for jointing on polymeric cables and wires made of PVC, XLPE, PE, EPR and utility cables. Application: Connections in industrial buildings, power supply in the ground, outdoors and underwater.
Colour	Black (BK)
Content	Cast resin PUR 771 Two-chamber pouch, transparent Moulding shells, transparent SF-system and nozzle Protective gloves, emery cloth, installation instructions HelaTape vinyl electrical tape Connector block with 5 screw connectors incl. allen key
Material	Polyurethane resin (PUR)
No. of Wires	5
PART DESCRIPTION	i-2 Premium / SF-PUR-BK
Pack Content	1 Set
Package Content packed in	set
Product Family	RELICON i-Line Premium SF with PUR 771
Product Group	Straight-through cable joints with connectors
Type	i-2 Premium / SF
Variant	Cast resin

Product Dimensions

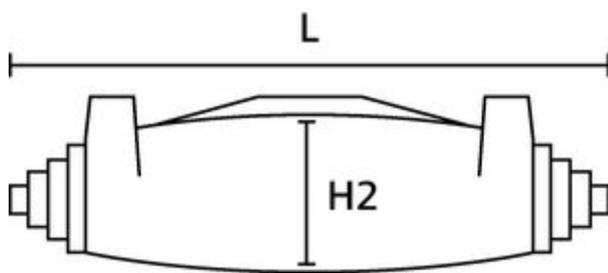

Conductor Size Range mm ²	1.5-16 mm ²
Height (H2)	49 mm
Length (L)	276 mm
Main Cabel max	5 x 16 mm ²
Main Cable min	5 x 1.5 mm ²

ELV Compliant (Article 4 - Z)	YES
Halogen-free	No
Hazardous Goods	No
Operating Temperature	-25 °C to +130 °C
ROHS compliant	Yes
Shelf Life	36 months
Specifications	
Voltage Range	0.6/1 kV

Logistics and Packaging

GTIN-13 / EAN	4031026627069
Packaging 1 - Height (m)	0.06 m
Packaging 1 - Length (m)	0.3 m
Packaging 1 - Qty	1
Packaging 1 - Type	carton
Packaging 1 - Volume (m ³)	0.00297 m ³
Packaging 1 - Weight (kg)	1.394 kg
Packaging 1 - Width (m)	0.165 m
Packaging 3 - Height (m)	0.305 m
Packaging 3 - Length (m)	0.345 m
Packaging 3 - Qty	10
Packaging 3 - Type	carton
Packaging 3 - Volume (m ³)	0.0326 m ³
Packaging 3 - Weight (kg)	14.44 kg
Packaging 3 - Width (m)	0.31 m
Packaging 4 - Height (m)	1.06 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	180
Packaging 4 - Type	pallet
Packaging 4 - Volume (m ³)	1.018 m ³
Packaging 4 - Weight (kg)	280.92 kg
Packaging 4 - Width (m)	0.8 m
Storage Temperature	+4 °C to +40 °C

More Information

