

CD50

Internal Decoy Camera

SURE

Overview

SURE Internal Decoy Camera

- British designed and manufactured
- Extremely realistic look
- 5 year flashing LED
- Sun shield
- No maintenance
- Very easy to install
- 5 year guarantee



CD50 - Internal Decoy Camera

Key Features and Benefits

SURE CD50 Decoy Camera - Indistinguishable from the real thing. British made conventional decoy camera.

The SURE24 internal decoy camera is maintenance free being constructed in high quality anodised aluminium with an anti corrosion finish.

The camera is mounted on an adjustable swivel wall bracket. The SURE24 decoy camera is supplied with a 5 year life flashing LED for realistic effect. 2 x AA Alkaline batteries are included.

Perfect for small commercial or domestic applications. Give an added level of security to a property with very little cost. This product is an excellent deterrent for many crimes.


RoSH Compliant

SURE

SURE24 Limited • 2 Moorbridge Court • Moorbridge Road East • Bingham • Nottinghamshire • NG13 8GG
Tel +44 (0) 1949 836 990 • Fax +44 (0) 1949 836 991 • Web www.sure24.co.uk • Email sales@sure24.net

Copyright 2009 SURE24 Limited • All rights reserved • SURE is a registered trademark.

Product Design

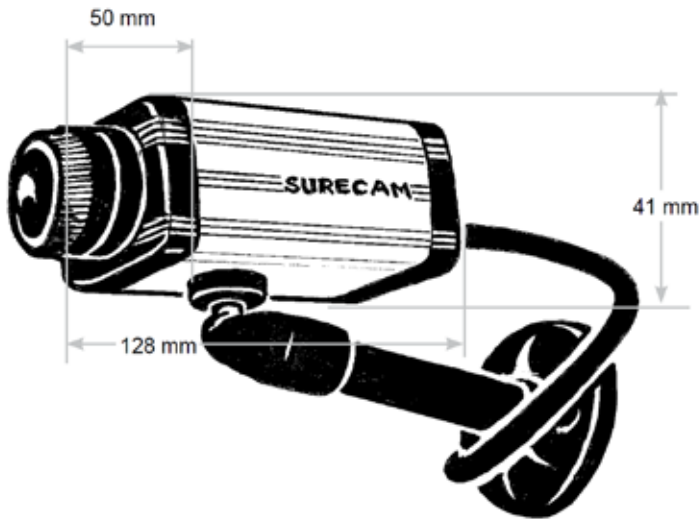

Specification

Feature / Function	Value / Data
Construction	Anodised Aluminium (Rust Free)
Swivel Bracket	Pan And Tilt (Angle Camera In Almost Any Direction)
Flashing LED	5 Year Life
Batteries	2 x AA Alkaline Batteries (Fitted)
Weight	274g
Design and Manufacture	England