


SERIE 8 PEZZI CHIAVI A PIPA CON FORO PASSANTE, BOCCHES ESAGONALI

STANLEY	Misure		
1-88-888	8, 10, 11, 13, 17, 19, 22, 24 mm.	<input type="checkbox"/>	<input checked="" type="checkbox"/>

CHIAVI REGOLABILI A RULLINO

- Forgiate al cromo vanadio
- Finitura satinata

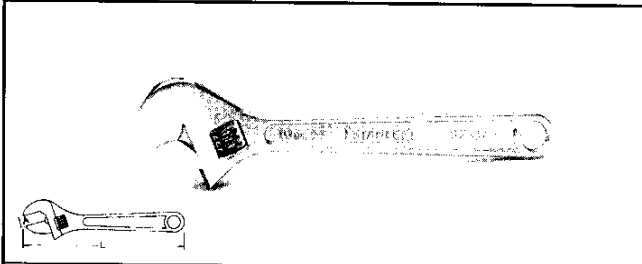


STANLEY	A mm	L mm
1-87-366	19	150
1-87-368	24	200
1-87-470	29	250
1-87-472	34	300
1-87-473	46	375
0-87-366	19	150
0-87-368	24	200
0-87-470	29	250
0-87-472	34	300

SET 10 CHIAVI A BRUGOLA IN ASTUCCIO

STANLEY	Misure
0-69-222	1,27 - 1,5 - 2 - 2,5 - 3 - 4 - 5 - 6 - 8 - 10 mm.

SET 8 CHIAVI A BRUGOLA CON ANELLO

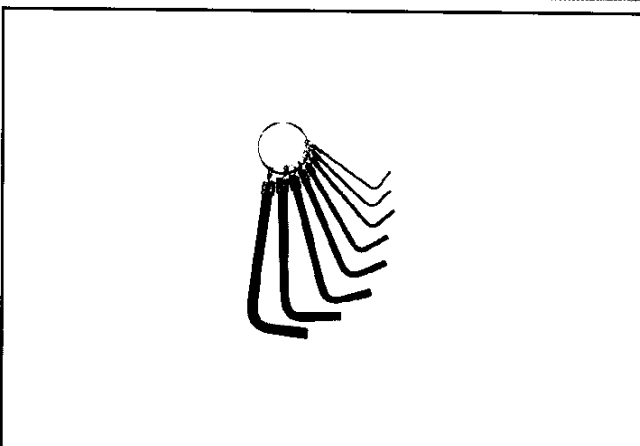

STANLEY	Misure		
1-69-241	1,5 - 2 - 2,5 - 3 - 4,3 - 5 - 6 - 8 mm.	<input type="checkbox"/>	<input checked="" type="checkbox"/>

SET 7 CHIAVI A BRUGOLA

- Con supporto tascabile

STANLEY	Misure		
4-69-262	2,5 - 3 - 4 - 5 - 6 - 8 - 10 mm.	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>

novità

SET 8 CHIAVI A BRUGOLA

- Con supporto tascabile

STANLEY	Misure		
4-69-261	1,5 - 2 - 2,5 - 3 - 4 - 5 - 5,5 - 6 mm.	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>

novità

SET 5 CHIAVI A BRUGOLA IN POLLICI

- Con supporto tascabile

STANLEY	Misure		
4-69-260	3/16" - 7/32" - 1/4" - 5/16" - 3/8"	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>

novità

SET 9 CHIAVI A BRUGOLA IN POLLICI

- Con supporto tascabile

STANLEY	Misure		
4-69-259	5/64" - 3/32" - 7/64" - 1/8" - 9/64" - 5/32" - 3/16" - 7/32" - 1/4"	<input checked="" type="checkbox"/>	<input checked="" type="checkbox"/>

novità