




LED Spot PAR30 Glass E27 DIM 8.6W (75W) 720lm 927 36°

Article number: 146499

BAI BaiSpot LED PAR30 E27 8.6W (75W) 720lm 2700K CRI90 36° Dimmable Glass 230V-240V 95x94mm LED-lamp

The so-called LED spots from the BaiSpot series are characterized by a much longer lifespan and significantly less energy consumption than their halogen predecessors. Due to the compact design, they are easily interchangeable. Spots are mainly used to provide directed light from the ceiling or wall. This version of the BaiSpot is dimmable. Use the correct LED dimmer. IP65 front disc: suitable for outdoor use if the lamp base is protected against contact with water. Ambient temperature range: -20°C to +40°C.

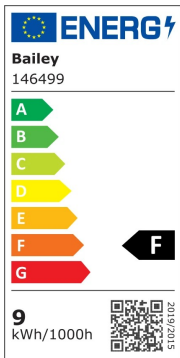

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED Spot PAR30 Glass E27 DIM 8.6W (75W) 720lm 927 36°
Brand	Bailey
Productseries	BaiSpot LED MV
Producttype	PAR30 Glass

ETIM specifications

Socket	E27
Luminous flux [lm]	720 - 720
Nominal voltage [V]	200 - 240
Lamp power [W]	8.6 - 8.6
Colour temperature [K]	2700 - 2700
Diameter [mm]	95
Length [mm]	94
Dimmable	Yes
Lamp shape	Reflector
Beam angle [°]	36 - 36
Colour	White
Type of glass/cover	Prism
Lamp designation	PAR30
Colour rendering index CRI	90-100
Voltage type	AC
Filament lamp	No
Luminous intensity [cd]	1600
Rated luminous flux according to IEC 62612 [lm]	720
Power factor	0.9
Lamp efficacy [lm/W]	83
Nominal current [mA]	33 - 33
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Grey
Average nominal lifetime [h]	25000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM5
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	9
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG1
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	Yes
Dimming phase cut-on (leading edge)	Yes
Dimming Touch and Dim	No

Dimming Zigbee	No
Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	F
With twilight switch	No
Material of light bulb	Glass

Complementary articles



140320
Ceiling / Wall Lamp Porcelain L
E27 Black



140321
Ceiling / Wall Lamp Porcelain L
E27 White