




## LED FIL WarmDim A60 E27 4W (40W) 470lm 927-922 Clear

Article number: 147208

BAI LED Filament WarmDim GLS A60 E27 4W (40W) 470lm Dimmable 927-922 Clear 230V-240V 320° 60x105mm D2W DTW Dim To Warm Dimtone Glowdim LED-lamp

With Bailey's WarmDim filament lamp you can go from cozy warm light (2200K) to functional warm white light (2700K) and back again in literally no time. The graceful dim-to-warm LED filaments also give this light source a similar appearance to that of the incandescent wires. Ideal, for example, in fixtures or pendant sets above (dining) tables or in floor lamps to create a living room atmosphere. Consult the dimmer list to choose the correct dimmer.

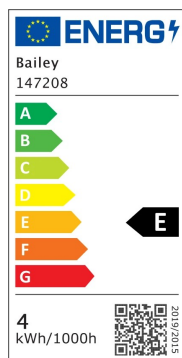

### General ETIM properties

|               |                                                      |
|---------------|------------------------------------------------------|
| ETIM group    | Lamps                                                |
| ETIM class    | LED-lamp/Multi-LED                                   |
| Name          | LED FIL WarmDim A60 E27 4W (40W) 470lm 927-922 Clear |
| Brand         | Bailey                                               |
| Productseries | LED Filament GLS                                     |
| Producttype   | A60 E27 927-922 CL                                   |

## ETIM specifications

|                                                 |                     |
|-------------------------------------------------|---------------------|
| Socket                                          | E27                 |
| Luminous flux [lm]                              | 470 - 470           |
| Nominal voltage [V]                             | 220 - 240           |
| Lamp power [W]                                  | 4 - 4               |
| Colour temperature [K]                          | 2200 - 2700         |
| Diameter [mm]                                   | 60                  |
| Length [mm]                                     | 105                 |
| Dimmable                                        | Yes                 |
| Lamp shape                                      | Pear-shape          |
| Beam angle [°]                                  | 320 - 320           |
| Colour                                          | White               |
| Type of glass/cover                             | Clear               |
| Lamp designation                                | A-type              |
| Colour rendering index CRI                      | 90-100              |
| Voltage type                                    | AC                  |
| Filament lamp                                   | Yes                 |
| Power factor                                    | 0.75                |
| Lamp efficacy [lm/W]                            | 117                 |
| Nominal current [mA]                            | 21 - 21             |
| Colour of light according to EN 12464-1         | Warm white < 3300 K |
| Housing colour                                  | Colourless          |
| Average nominal lifetime [h]                    | 15000               |
| Degree of protection (IP)                       | IP20                |
| Colour consistency (McAdam ellipse)             | SDCM6               |
| Min. number of switching cycles                 | 15000               |
| Weighted energy consumption in 1000 hours [kWh] | 4                   |
| Remote operation possible                       | No                  |
| With movement sensor                            | No                  |
| With remote control                             | No                  |
| Photobiological safety according to EN 62471    | RG0                 |
| Compatible with Apple HomeKit                   | No                  |
| Compatible with Google Assistant                | No                  |
| Compatible with Amazon Alexa                    | No                  |
| IFTTT support available                         | No                  |
| Suitable for electronic ballast                 | No                  |
| Suitable for magnetic ballast                   | No                  |
| Dimming phase cut-off (trailing edge)           | Yes                 |
| Dimming phase cut-on (leading edge)             | Yes                 |
| Dimming Touch and Dim                           | No                  |
| Dimming Zigbee                                  | No                  |
| Dimming Bluetooth                               | No                  |

|                                                              |       |
|--------------------------------------------------------------|-------|
| Dimming Wi-Fi                                                | No    |
| Energy efficiency class according to EU regulation 2019/2015 | E     |
| With twilight switch                                         | No    |
| Material of light bulb                                       | Glass |

## Alternative articles



**145415**  
LED FIL WarmDim Basic A60  
E27 4.5W (37W) 420lm 927-922  
Clear

## Complementary articles



**145020**  
Pendant Fuji E27 Black 1.5M 2C  
Black



**145664**  
Pendant Vigo E27 Black 1.5M  
2C Black