


Features

- IEC-584-3
- Good temperature resistance (not suitable in fluids)
- Bare Tail termination

RS PRO Glassfibre insulated Flat Pair IEC Exposed Junction Thermocouple with Bare Tails - Type K

RS Stock No.: 0652765

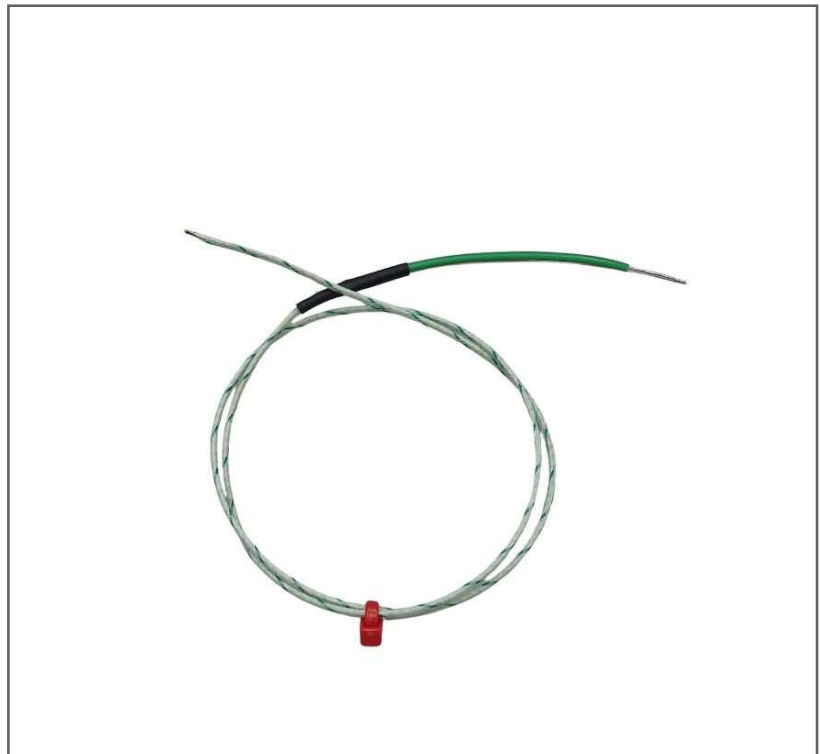

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Exposed junction thermocouples are often used in applications where fast response times are crucial, such as in research laboratories, semiconductor manufacturing, and certain industrial processes.

General Specifications

Thermocouple Type	Type K
Temperature Measurement Range	-60°C to +350°C (short periods up to 400°C)
Construction	Fast response, welded exposed junction
Measuring Junction	Exposed
Standards Met	IEC
Application	Good temperature resistance (not suitable in fluids)

Mechanical Specifications

Termination	Bare Wire
Length	0.3m (0.98ft)
Cable Insulation	1/0.508mm Glassfibre Flat pair

Approvals

Declarations	RoHS
--------------	------

Similar Products

Colour Code	Type	Style	Cable Size	Length	Termination	RS Stock#
IEC	K	GLASSFIBRE	1/0.508mm	0.3m (0.98ft)	Bare Tails	0652765
IEC	K	GLASSFIBRE	1/0.508mm	1m (3.3ft)	Bare Tails	1236314
IEC	K	GLASSFIBRE	1/0.508mm	2m (6.56ft)	Bare Tails	8722795
IEC	K	GLASSFIBRE	1/0.508mm	5m (16.4 ft)	Bare Tails	8722799
IEC	K	GLASSFIBRE	1/0.508mm	10m (32.8ft)	Bare Tails	1236315