




Datasheet

Stock No: 682-129

ENGLISH

RS Pro Tool Steel Rectangular Bar, 500mm x 20mm x 5mm

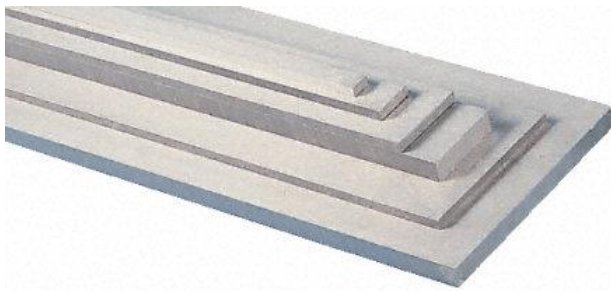

Product Details:

Ground Flat Stock - Metric & Imperial

- High quality tool steel fully annealed and free from carburisation
- Precision ground to close tolerances, enables finished components to be produced with minimum machining
- Suitable for hardening with excellent dimensional stability and resistance to wear
- Conforms to BS4659: 1971 BO1
- Applications include gauges, punches, dies, jigs, templates, cams, machine parts etc.
- Tolerance Imperial; W -0.000 +0.005in;T -0.001 +0.001in
- Tolerance Metric; W -0.000 +0.127mm;T -0.000 +0.050 mm

Specifications:

Material: Tool Steel
Form: Rectangular Bar
Length: 500mm
Width: 20mm
Thickness: 5mm