


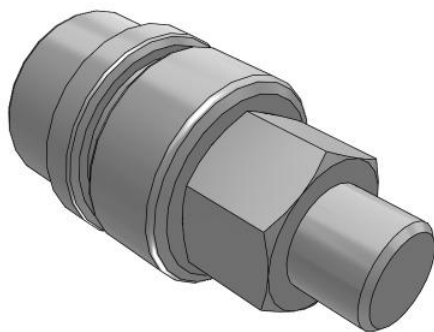

KKH*S-*M, S-Couplers, Male Thread KKH4S-02MS

Datasheet


General series information

- Male thread.
- Body size: 1/8, 1/4.
- Applicable Port Size: R1/8, R1/4, R3/8, R1/2.

Standard specifications

Body Size	4 (1/4)
Piping Port Size	R 1/4
Pressure medium	Air, Water
Maximum operating pressure	0 - 1.0 MPa
Minimum operating pressure	0 kPa
Proof pressure	1.5 MPa
Maximum ambient temperature	60 °C / 40 °C for Water
Minimum ambient temperature	-5 °C (with no freezing) / 5 °C for Water
Effective Area	39 mm ²
Sealing principle	Electroless nickel plated (copper-free application), With male thread sealant
Connection plug	Series KK plug
Weight	0.060 Kg

Dimensions

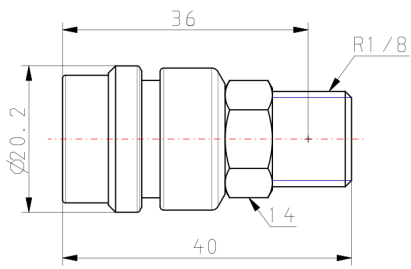

Additional information

Catalogue

[KK-C_EU.pdf](#)