
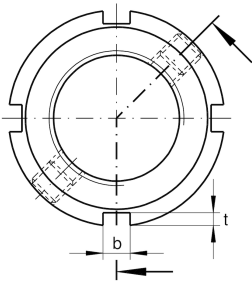


ZM85

Precision locknut

Precision locknut ZM, accessory ZM..

Technical information

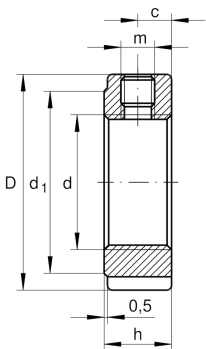

Main Dimensions & Performance Data

d	M85X2	Thread
D	110 mm	Outside diameter
h	18 mm	Height
M _A	15 Nm	Mounting torque set screw
F _{aB}	385,000 N	Breaking load, axial
M _L	320 Nm	Breakawag
M _{AL}	190 Nm	Mounting torque reference
M _M	13.1 kg*cm ²	Mass moment of inertia

≈m 0.524 kg Weight

Dimensions

d ₁	102 mm	Plant diameter outside
t	3.5 mm	Hight retaining slot
b	8 mm	Width retaining slot
c	9 mm	Distance bore
m	M8	Threaded - threaded pin