




C 9

E0845318
C-SLEEVE CONNECTORS 50mm2

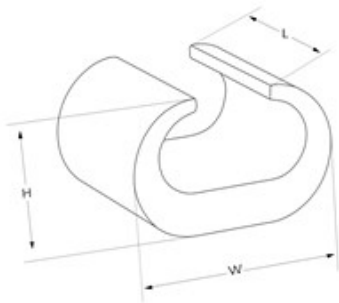

Product Properties:

Suitable for Class 1 conductor	Yes
Suitable for Class 2 conductor	Yes
Suitable for solid cores	Yes
Max Temp	150 °C
Surface protection	Bare
Material	Copper

Dimensions:

H	18 mm
L	23 mm
W	28 mm
MOQ	50 .
Unit	pcs
Cross section through-wiring core	50 mm²
Cross section branch core	50 mm²
Nominal cross section	50 mm²
Length	23 mm

Approvals:

Approved according to CE	Yes
--------------------------	-----

Compliance:

Conflict Minerals	N/A, Contains no conflict minerals
-------------------	------------------------------------

Extended Minerals	N/A, contains no extended minerals
PFAS	No PFAS
REACH	No SVHC (Latest. 21 Jan 2025)
RoHS	RoHS 3 (2015/863)
SCIP	Not Applicable
ECCN (EU)	No CLASS
ECCN (US)	EAR99

Other information:

ETIM-Class	EC002290 - C-clamp for round wire
ETIM-Release	DYNAMIC
Trademark	NEMIQ
Product Group	Branch connectors
Search Description	AVGREININGS / C-HYLSA
Alternative SKU	C9
E-no	E0845318

Logistic information:

Barcode	733117612264
Country of origin	CN
E-no	E0845318
Item status	Stock item, normally in stock with reservation for in between sales.
MOQ	50 .
Stock code	C 9
Taric code	85369010
Unit	pcs

*We reserve the right to make technical changes and disclaim any typographical errors.