



Actuator shown in pos. 1

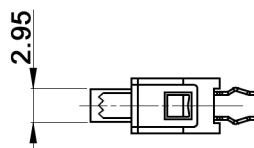

P.C. MOUNTING

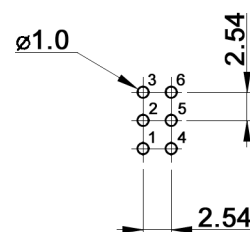

CONTACT ARRANGEMENT

code for x	function	actuator in position 1	actuator opposite to pos. 1
D	On-On	1-2, 4-5	2-3, 5-6

code for x	function	actuator in position 1	actuator in center	actuator opposite to pos. 1
E	On-Off-On	1-2, 4-5	open	2-3, 5-6

Specifications:

Contact rating: max. 0.4VA, max. 48V AC or DC, max. 50mA
min.: 1µA, 20mV AC or DC

Contact resistance: 50mOhm max.

Insulation resistance: 500MOhm min. at 250V DC

Dielectric strength: 500V, 50Hz for the duration of 1 minute

Operating temperature: -20°C to +85°C

Electrical life: min. 40 000 cycles

Soldering conditions: wave-soldering: 260 +/-5°C, 5 +/-1sec.

Protection: IP67

Material: Actuator: PBT, yellow

Housing: brass, nickel plated

Case: PBT, meets (UL94V-0), washable

Contact / terminals: phosphor bronze, gold plated over nickel barrier

Cap: silicone rubber



Tolerances: 0.00: ±0.25mm 0.0: ±0.40mm	Date	Name
	03/14	dr

ASE 2 x

knitter-switch

30 30 61

Page

1/1

Hood dimension	04/14	dr
Modifications	Date	Name