

2 Port USB HDMI KVM Switch with Audio and USB 2.0 Hub

Product ID: SV231HDMIUA





The SV231HDMIUA 2-port USB HDMI® KVM Switch lets you control two USB-enabled multimedia computers or devices with HDMI video interfaces, using a single peripheral set/console (USB keyboard, mouse, monitor, speakers and microphone).

A highly versatile KVM solution, the USB HDMI KVM Switch features an integrated 2-port USB 2.0 hub that lets selected computers access shared high speed USB devices, eliminating the cost of duplicate USB peripheral purchases.

Ensuring high quality video capability, the HDMI KVM switch supports HD resolutions of up to 1920 x 1200. Offering genuine digital signal transmission over the cable, this switch can be used to share one HD panel between multiple HDMI sources such as Blu-Ray players, Video Game consoles and HD media centers.

The switch also supports audio and microphone switching functions and allows you to select connected computers, USB device hub ports and audio/mic channels either simultaneously or independently using either front-panel push-buttons or keyboard hotkeys.

This product is TAA compliant and backed by a Startech.com 3-year warranty with free lifetime technical support.

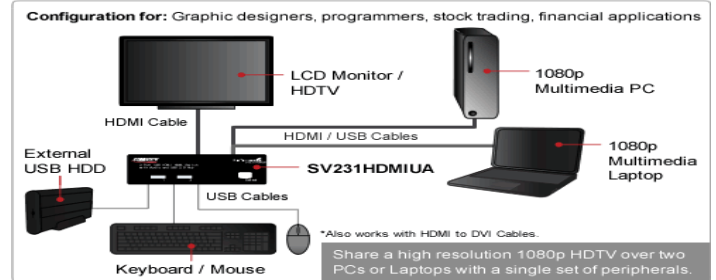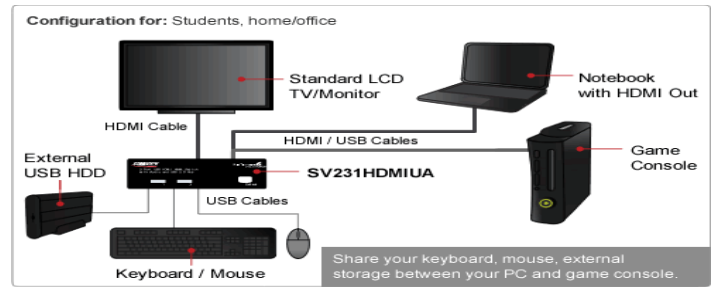

Certifications, Reports and Compatibility



Applications

- Ideal for sharing two newer HDMI® multimedia PCs with an HDMI monitor
- Students can use a single monitor and connect their gaming console along side their PC or laptop
- Allows multimedia PCs to share peripherals and a single high definition television
- Use in the Office to connect two multimedia PCs to a single console connection increasing productivity

Features

- Supports push button and hotkey PC Switching
- Integrated USB 2.0 hub - Share USB peripherals between PCs
- Supports High Resolutions Digital video up to UXGA (1600x1200), WUXGA (1920x1200), and 1080p (1920x1080)
- No software drivers required; OS independent
- Supports Plug&Play operation
- Supports both HDMI® audio and 3.5mm analog audio
- Independent Audio switching
- Audible tone to indicate PC switching
- User-defined scan time intervals
- Manual video adjustments via rear function button

Hardware	Warranty	3 Years	
	Audio	Yes	
	Cables Included	No	
	Daisy-Chain	No	
	KVM Ports	2	
	Number of Monitors Supported	1	
	PC Interface	USB	
	PC Video Type	HDMI	
	Rack-Mountable	No	
Performance	Hot-Key Selection	Yes	
	IP Control	No	
	Maximum Digital Resolutions	1920 x 1200	
	Maximum Number of Users	1	
	MTBF	126813 hours	
	On-Screen Display	No	
	Port Selection Support	Push Button and Hotkeys	
	Wide Screen Supported	Yes	
Connector(s)	Console Interface(s)	1 - HDMI (19 pin) Female 2 - 3.5 mm Mini-Jack (3 Position) Female 4 - USB Type-A (4 pin) USB 2.0 Female	
	Host Connectors	2 - HDMI (19 pin) Female 2 - USB B (4 pin) Female 4 - 3.5 mm Mini-Jack (3 Position) Female	
	Software	OS Compatibility	OS independent; No software or drivers required
	Indicators	LED Indicators	2 - Online/Active (Green - Connected PC is online, Red - PC is selected)
		Power	Center Tip Polarity
		Input Current	0.8A
	Input Voltage	110V-240V AC	
	Output Current	1.5A	
	Output Voltage	12 DC	
	Plug Type	M	

	Power Consumption (In Watts)	18
	Power Source	AC Adapter Included
Environmental	Humidity	0~80% RH
	Operating Temperature	0°C to 40°C (32°F to 104°F)
	Storage Temperature	-20°C to 60°C (-4°F to 140°F)
Physical Characteristics	Color	Black
	Enclosure Type	Steel
	Product Depth	2.8 in [70 mm]
	Product Height	1.6 in [40 mm]
	Product Weight	22.4 oz [634 g]
	Product Width	4.9 in [124.8 mm]
Packaging Information	Shipping (Package) Weight	2.4 lb [1.1 kg]
What's in the Box	Included in Package	1 - 2 Port HDMI KVM
		1 - Package of Rubber feet
		1 - Power Adapter
		1 - User Manual

Product appearance and specifications are subject to change without notice.