


Datasheet

Size 2 bar handle, Fixing centre 127.0mm

RS Stock number 583-820



STYLE 10 ●

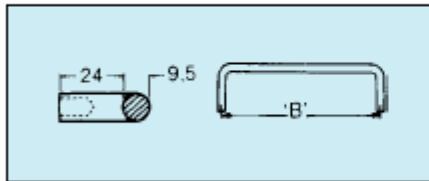

- Material : 9,5mm dia mild steel
- Finish : Polished chrome
- Fixings : ISO M5 x 10mm pan head screws and washers.
ISO M5 Nyloc hexagon nuts, flat washers and studs


Ordering information

B	Order code
101,6	549-10007B
127,0	549-10008K
152,4	549-10009G
203,2	549-10010H

The Veronex hand held range have been designed for a variety of portable applications including data aquisition, field test and measurement.

The size 1 units, are supplied with the belt clip fitted as standard, but do not have a LCD cut out or recessed area for membranes. Unique to the two larger units are the top covers which feature a recessed membrane keypad area designed to accept a 74mm x 40mm (size 2) or 96mm x 60mm (size 3) membranes and an LCD cutout to accept meters and displays.

The size 2 units will accept a 40mm x 20mm LCD (viewing area 31 x 14mm) and size 3 will accept a 60 x 30mm LCD (viewing area 47 x 18mm).

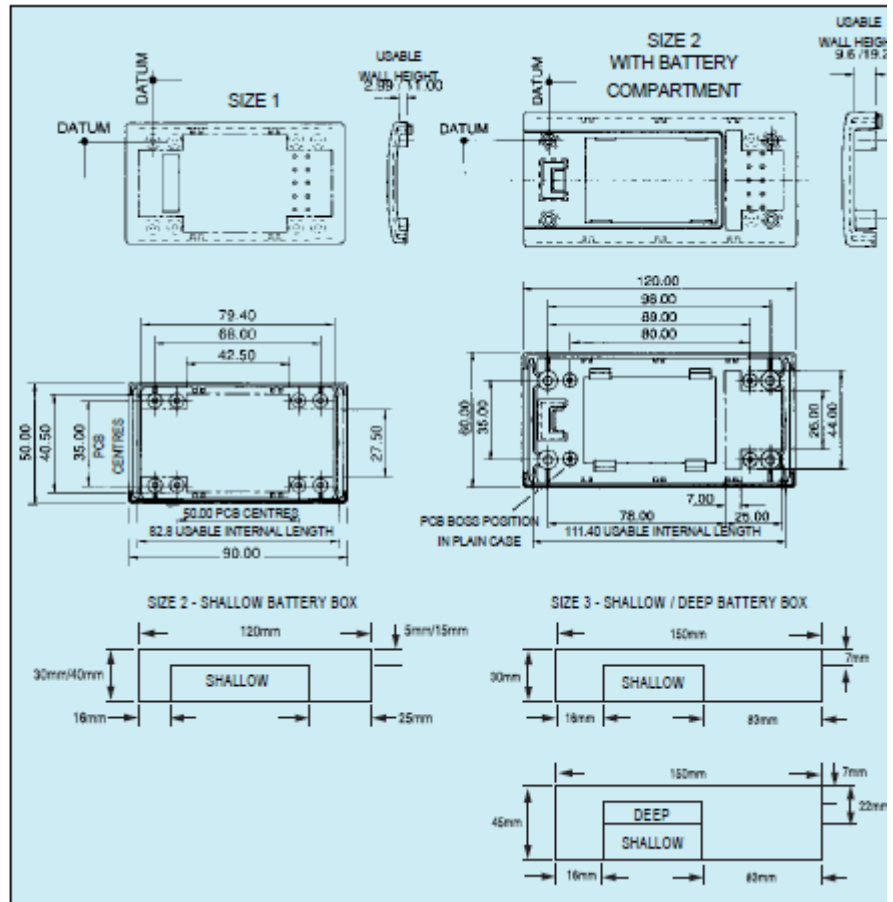

VERONEX HAND-HELD ENCLOSURES

Ordering information

Size	Description	Dimensions			Order code
		H	W	D	
1	With belt clip	90	50	16	75-228111E
1	With belt clip	90	50	24	75-228112B
2	Without battery compartment	120	60	30	75-228113K
2	With battery compartment	120	60	30	75-227909F
3	Without battery compartment	150	80	30	75-228114G
3	With battery compartment	150	80	30	75-227910G
3	Without battery compartment	150	80	45	75-228115D
3	With battery compartment	150	80	45	75-227911D