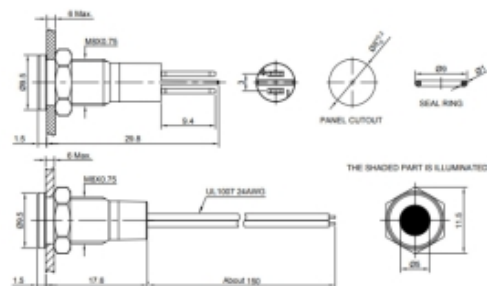


[View Product Page](#)

DX Range	Yellow
8mm Diameter	24V
solder Lug	Nickel Plated Brass

Product Display Title:	8mm Vandal Resistant Indicator DX Range
Product Family:	Indicators
Product Series:	8mm Vandal Resistant Indicator DX Range
Bezel Finish:	Polished
Body Colour:	Nickel
Body Material:	Brass
Body Material Type:	Metal
Diameter:	8mm
Dielectric Withstanding Voltage:	1500V
Function:	Vandal Resistant Indicator
Illumination Colour:	Yellow
Illumination Voltage:	24V
Indicator Profile:	Flat-round
Insulation Resistance:	≥100MΩ(500VDC)
Ip Rating:	IP67
Material Finish:	Polished
Max Operating Temperature:	55°C
Min Operating Temperature:	-25°C
Max Panel Thickness:	6mm
Panel Cut Out:	8mm Diameter Circle
Rohs Compliant:	Yes
Thread Size:	M8 X 0.75

 6mm & 8mm Vandal Resistant...

 DX08LY024N3D CAD Model