

## Datasheet

### Sealed Sub-Miniature Toggle Switch


RS Stock number 734-7176



#### Specifications:

MECHANICAL LIFE:	30,000 make-and-break cycles.
CONTACT RESISTANCE:	20m $\Omega$ max. initial @ 2-4VDC 100mA for both silver and gold plated contacts
INSULATION RESISTANCE:	1000M $\Omega$ min.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
OPERATING TEMPERATURE:	-30°C to 85°C.
CASE & BUSHING:	Glass filled nylon 6/6, retardant, heat stabilized (UL94v-0)
ACTUATOR:	Brass, chrome plated
CONTACT/TERMINAL:	Silver or gold plated copper
SWITCH SUPPORT:	Brass, tin plated

Dimensions – inch  
mm

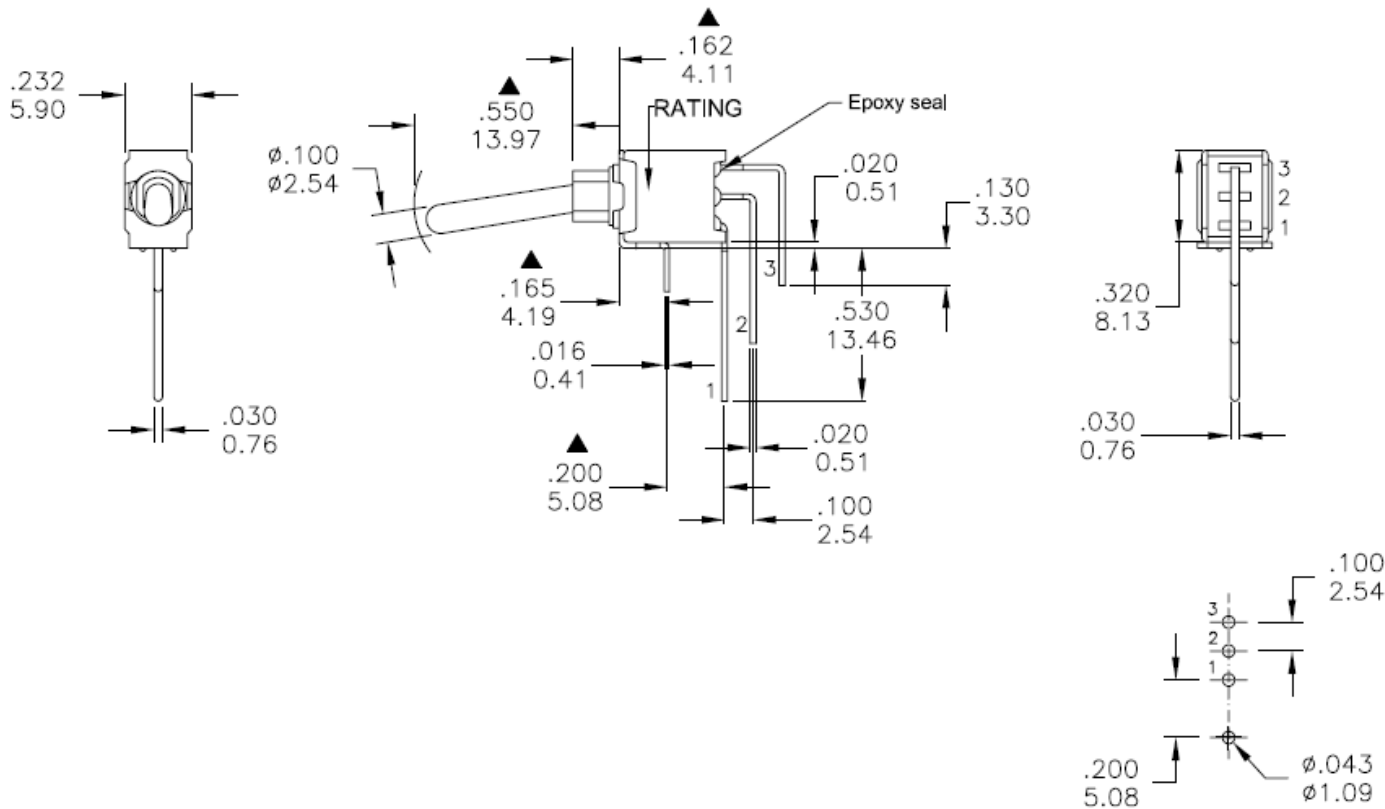

Model No.	POS.1	POS.2	POS.3
2AS1	ON	NONE	ON
Term. Comm.	2-3	N/A	2-1
SCHEMATIC			

SWITCH FUNCTION

P.C. MOUNTING