


Blue Elastic Rubber Trolley Wheel 125mm, ball bearings, 300kg

Elastic Rubber-tyred wheel

PRODUCT

Article number **571-511-125B20**

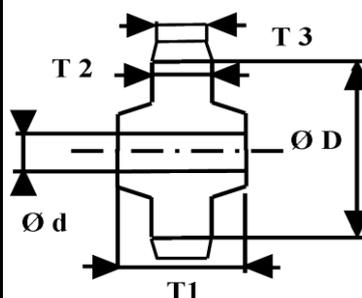

Product Details

Wheel Rim : very thick black polyamide.
 Tyre : solid, blue bonded elastic rubber tyre, non marking.
 Hub : symmetrical, two ball bearings.

Specifications

| | |
|--|---------------------------------------|
| Wheel Diameter - $\varnothing D \pm 1\%$ | 125 mm |
| Hub Type | two ball bearings |
| Hub Length T1 | 55 mm ± 1 |
| Width of Tread T2 | 50 mm ± 1 |
| Width of Tread-on floor T3 | 48 mm ± 1 |
| Axle Hole $\varnothing d$ | $\varnothing 20$ mm |
| Hardness of tread A ± 4 | A 70 Shore |
| Load capacity | 300 Kg |
| Temperature | -20 / +60 °C |
| Weight | 0,58 kg |
| | |
| | |

TECHNICAL DATA

Applications :

Sensitive materials handling on uneven surfaces.
 Resilient with a low starting effort.
 Does not leave scratches or other marks on surfaces.
 Reduce schok and vibration.
 Quiet in use and high wear resistance.
 Towable by mechanized vehicle.
 Suitable for industrial floors and also all interior floors.