

Features

- Panel mounting type
- Offer 5 poles
- Solder type termination

Female DIN
connector jack

RS PRO DIN Connectors

RS Stock No.: 0360112



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description


Buy this product from www.rspro.com

- Enables a secure signal and current transmission
- Can be used in various applications to connect devices including, personal computers, audio and video to power, serial and data

Product range

Parameters	0360112
Number of Contacts	5
Gender	FEMALE
Mating Type	Panel Mount
Termination Method	Solder
Body Orientation	Straight
Shielded/Unshielded	Shielded
DIN Number	DIN 45326
Housing Material	PBT
Contact Plating	Silver
Contact Material	Copper
Current Rating	1A
Voltage Rating	100V
Contact Resistance	<30 mΩ
Insulation Resistance	50 mΩ Min @ 500 V dc
Withstands Voltage	500 V ac
Dielectric Strength	1000V AC/1 Minute
Rated impulse voltage	2500 V
Applicable Wires	AWG 22-26
Cross-sectional area	max. AWG 20
Minimum Operating Temperature	-20°C

Maximum Operating Temperature	85°C
Pollution degree	2
IP Rating	IP40
Cable outlet	2.5 - 6.0 mm
Mechanical operation	> 500 Mating cycles
Compliance/Certifications	UL94-V0

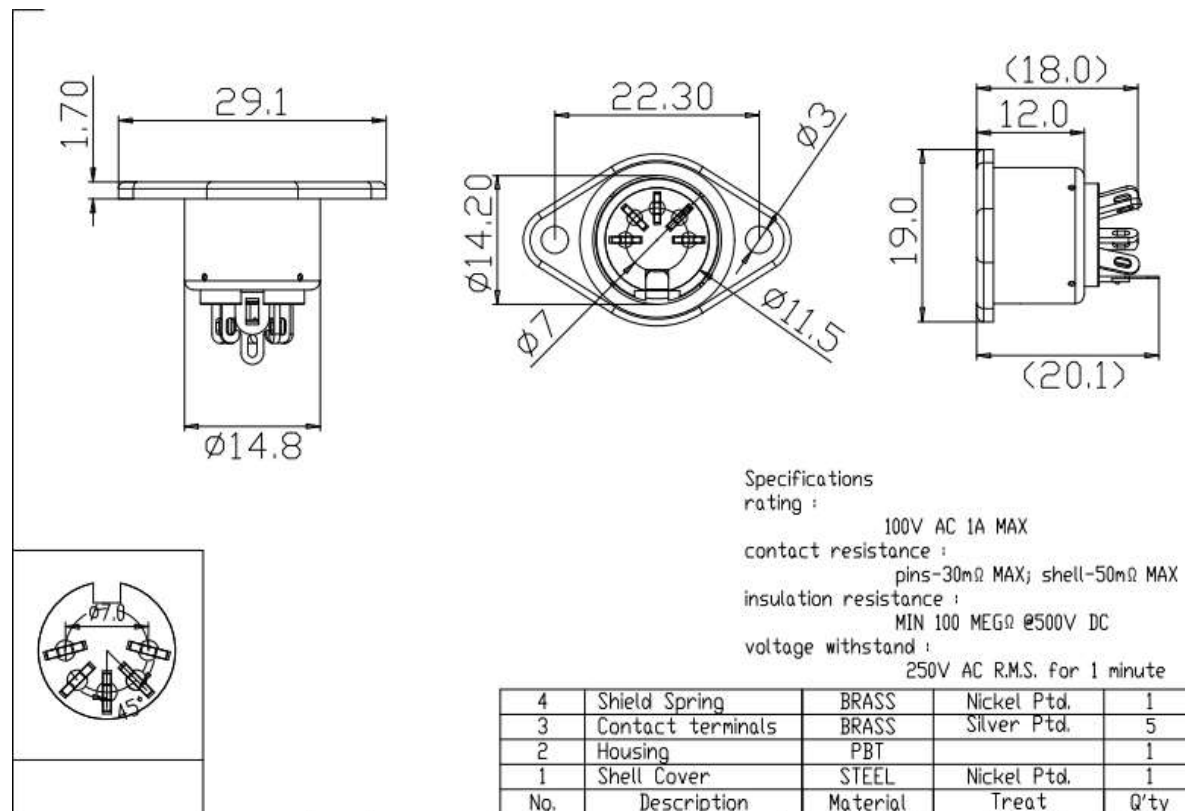

0360112