


PREVOS1 SAFETY QUICK COUPLINGS - CSI 06

Female thread twin coupler

Profile : ISO 6150C



Part number	Female thread	Min. operating pressure (bar)	Flow rate at 6.00 bar (l/min) ($\Delta P = 0.60$ bar)	ID passage (mm)	Temperature min/max (°C)
CSI 068101	G1/4	2.00 / 12.00	833.00	6 mm	-15.00 / 70.00
CSI 068102	G3/8	2.00 / 12.00	833.00	6 mm	-15.00 / 70.00
CSI 068103	G1/2	2.00 / 12.00	833.00	6 mm	-15.00 / 70.00

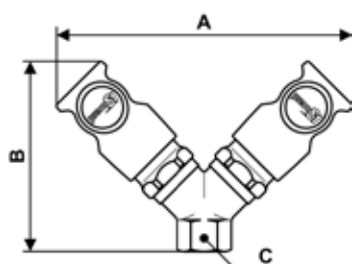

Part number	Dim. A (mm)	Dim. B (mm)	Dim. C (mm)
CSI 068101	101.00	68.00	17.00
CSI 068102	116.00	74.00	20.00
CSI 068103	125.00	82.00	25.00