




## LED FIL XTRA A60 E27 5W (75W) 1055lm 830 Clear Class A

Article number: 146966

BAI LED Filament XTRA GLS A60 E27 5W (75W) 1055lm 3000K Clear Class A 230V-240V 320° 60x105mm 35.000h LED-lamp

For several years now, regular Led Filament lamps have been the sustainable version of incandescent, halogen and energy-saving lamps that consume less power and last longer. The Bailey Led Filament Xtra goes a step further in terms of durability. The Xtra is so sustainable that it can bear the energy efficiency label A. With the introduction of the new energy labels in 2021, the status now has one at last. The lamp lasts no less than 35.000 burning hours, has 1055lm and only produces 5W. It is in terms of light output which makes it equivalent to the 75W incandescent lamp which gave more heat than light and wasted a lot of energy. The warm 3000K light color is attractive and friendly to the eye. With the normal E27 lamp base for all Bailey (decorative) lamp holders, table lamps, fixtures and pendant sets.

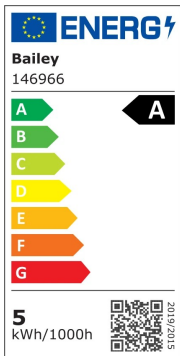

### General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	LED FIL XTRA A60 E27 5W (75W) 1055lm 830 Clear Class A
Brand	Bailey
Productseries	LED Filament GLS
Producttype	A60 XTRA

## ETIM specifications

Socket	E27
Luminous flux [lm]	1055 - 1055
Nominal voltage [V]	220 - 240
Lamp power [W]	5 - 5
Colour temperature [K]	3000 - 3000
Diameter [mm]	60
Length [mm]	105
Dimmable	No
Lamp shape	Pear-shape
Beam angle [°]	320 - 320
Colour	White
Type of glass/cover	Clear
Lamp designation	A-type
Colour rendering index CRI	80-89
Voltage type	AC
Filament lamp	Yes
Rated luminous flux according to IEC 62612 [lm]	1055
Power factor	0.5
Lamp efficacy [lm/W]	211
Nominal current [mA]	40 - 40
Colour of light according to EN 12464-1	Warm white < 3300 K
Housing colour	Colourless
Average nominal lifetime [h]	35000
Degree of protection (IP)	IP20
Colour consistency (McAdam ellipse)	SDCM6
Min. number of switching cycles	15000
Weighted energy consumption in 1000 hours [kWh]	6
Remote operation possible	No
With movement sensor	No
With remote control	No
Photobiological safety according to EN 62471	RG0
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No
Suitable for electronic ballast	No
Suitable for magnetic ballast	No
Dimming phase cut-off (trailing edge)	No
Dimming phase cut-on (leading edge)	No
Dimming Touch and Dim	No
Dimming Zigbee	No

---

Dimming Bluetooth	No
Dimming Wi-Fi	No
Energy efficiency class according to EU regulation 2019/2015	A
With twilight switch	No
Material of light bulb	Glass