


## FEATURES

- **Metal Detectable:**  
Enhances safety by allowing detection in food and pharmaceutical environments
- **Nylon Material:** Provides durability and resistance to wear and tear
- **Length of 380 mm:** Suitable for bundling larger cable groups
- **Tensile Strength of 39 kg:** Ensures secure fastening of cables
- **Maximum Bundle Diameter of 105 mm:** Accommodates a wide range of cable sizes
- **Operating Temperature up to 85 °C:** Suitable for use in various temperature conditions
- **Compliance with RoHS and UL 94HB:** Meets key safety and environmental standards

## RS PRO Metal Detectable Cable Tie, 380 mm Nylon

RS Stock No: 656-078

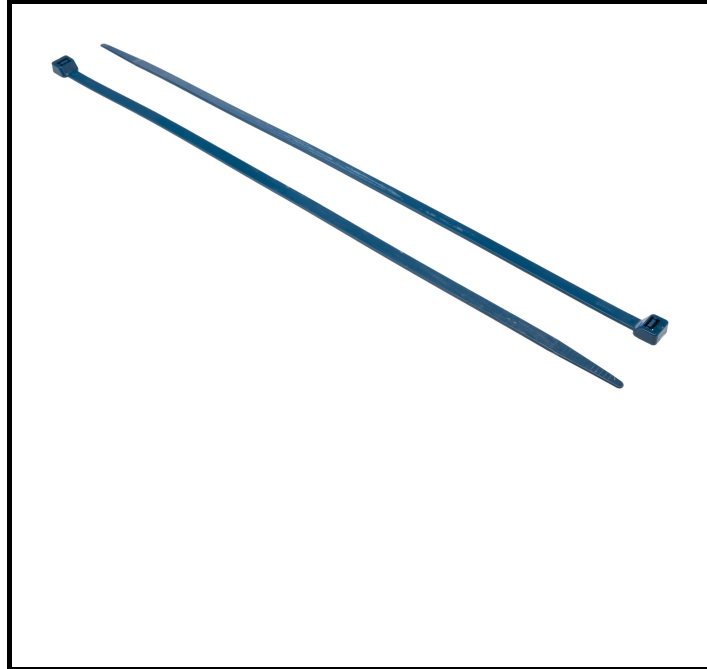

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

RS PRO offers a reliable solution for securing cables and wires with its Metal Detectable Cable Tie. Designed for environments where detection is crucial, this cable tie ensures safety and compliance in sensitive areas. Its robust construction and detectable properties make it ideal for use in food processing and pharmaceutical industries.

### General Specifications

Colour	Blue
Product Type	Cable Tie
Sub Type	Metal Detectable
Tensile Strength	39 kg

### Protection Category

Fire Behaviour	UL 94HB
UV Resistant	No

### Mechanical Specifications

Length	380 mm
Material	Nylon
Maximum Bundle Diameter	105 mm
Width	7.6 mm

### Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

### Approvals

Standards/Approvals	RoHS, UL94HB
---------------------	--------------

