


## E Y C A S A

The home and door wireless video set sets new standards. Following its motto "see, speak, hear and operate" Eycasa combines video surveillance, door intercom and opening in one system – exclusively from ABUS. It offers a smart combination of security and comfort and answers flexibly to following its motto residents' wishes. Thanks to wireless radio transmission, Eycasa is simply installed in existing buildings and can even extend a built-in system at all times.

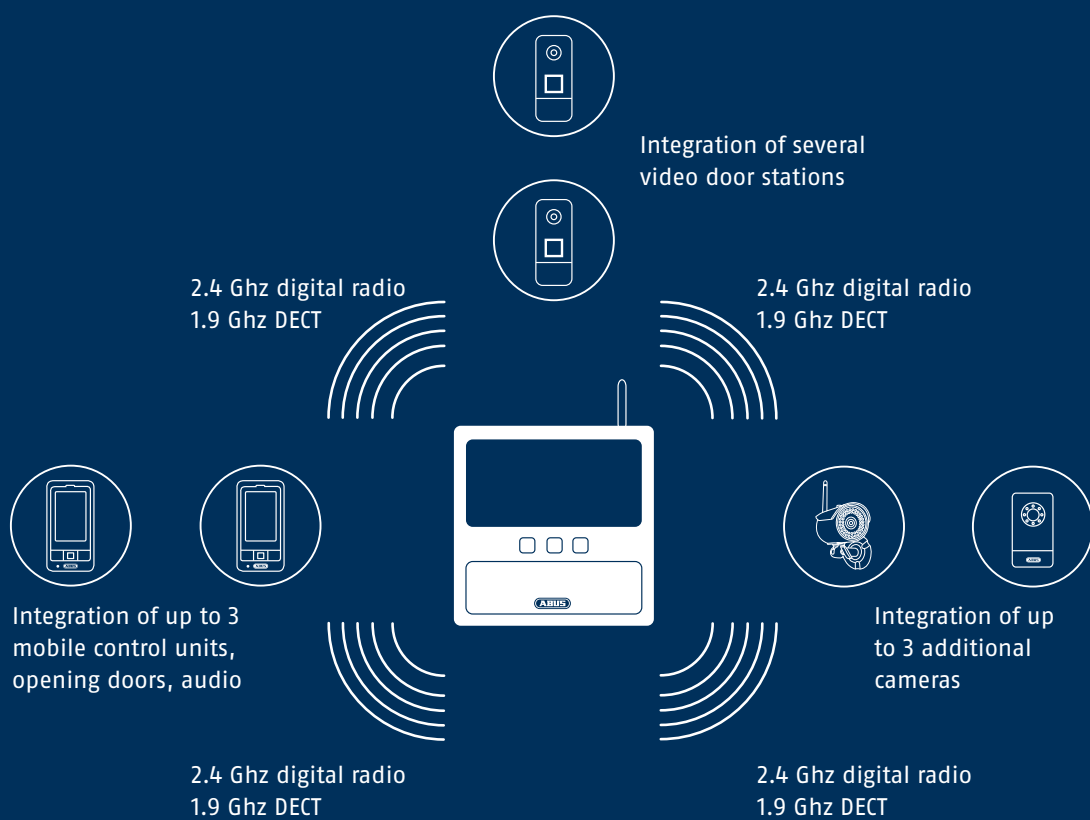

# Eycasa Wireless Door Intercom System



- Complete door & house wireless video system for seeing, speaking, listening and operating (door opener)
- The set includes a video door station and main unit
- Secure wireless transmission (2.4 GHz/DECT ~1880 MHz)
- Door opener plus video surveillance with up to 4 cameras
- Night vision in close proximity to the camera (IR LEDs)
- Powered using the bell transformer or batteries
- 3 wireless cameras and 3 handsets can be added
- Optional: Family Care Camera as a baby monitor or for senior care
- Ideal for retrofitting in existing buildings – exclusively from ABUS



Security and comfort in one package: The Eycasa Wireless Door Intercom. The Eycasa Video Door Station offers an intercom, door opener and video system in one. The set-up is easy as this product has the same dimensions as common intercom systems. It can be mounted horizontally as well as vertically and even power supply. With its 7" touch screen the portable base station is easy to use – and offers up to 30 m radio range. Extensibility: the Video Base Station is able to add up to 3 additional cameras and 3 Eycasa Mobile Handsets.

# Eycasa Wireless Door Intercom System



Article number	CASA31000
----------------	-----------

Description	Eycasa Wireless Door Intercom System
	Eycasa Main Unit
Connectable products	Eycasa Video Door Station, Eycasa FamilyCare Camera, Eycasa Outdoor Camera, Eycasa Mobile Handset
Monitor	7" touch screen LCD
Local Functions	1-/4-fold view, change of view on alarm, alarm lists, intercom function, door opener
Resolution live view	640 x 480
Number of channels	4
Resolution modes	1 x 640 x 480 @ 20 fps/4 x 320 x 240 @ 12 fps
Radio range	30 m
Microphone	Integrated
Audio	Loudspeaker
Mounting	Table mounting, wall mounting
Adjustable alarm tone	5 ring tones
Network connection LAN	RJ45 10/100 Mbit
Connections	SD card, Ethernet
Protection class IP	34
Power supply DC	12 V
Storage medium	SDHC card, max. 32 GB
Power consumption	400 mA
Video compression	MPEG-4, MJPEG
Dimensions (W x H x D)	185 x 200 x 100 mm

	Eycasa Video Door Station
Image sensor	1/4" CMOS sensor
Resolution	640 x 480
Radio range	30 m
Housing material	Plastic ABS, white
Alarm	Door bell signal on Base Station
Video compression	MPEG-4
Scope of delivery	Eycasa Main Unit • Eycasa Video Door Station • Power supply incl. EU-, AUS- and UK adapter • Wall mounting • Mounting material • Quick Guide • User manual on CD

Price excl. VAT	Conditions for dealers on request
-----------------	-----------------------------------

Article number	CASA30100
----------------	-----------

Description	Eycasa Video Door Station
Image sensor	1/4" CMOS sensor
Resolution	640 x 480
Radio range	30 m
Housing material	Plastic ABS, white
Alarm	Door bell signal on Base Station
Frame rate	20 fps
Focal length	2.5 mm
Horizontal angle of view	80°
IR range	2 m
Audio	Integrated loudspeaker and microphone
Orientation	Horizontal or vertical
Battery power	Yes – optional possible with CASA30150 (ca. 7 months)
Battery type	6 x Lithium AA 3.6 V, 2200 mAh
Microphone	Integrated
Relais output	2
Protection class IP	55
Power supply AC	24 V
Power supply DC	12 V
Power consumption	380 mA
Video compression	MPEG-4
Dimensions (W x H x D)	315 x 135 x 32 mm

Scope of delivery	Eycasa Video Door Station • Mounting material • Quick Guide
-------------------	---

Price excl. VAT	Conditions for dealers on request
-----------------	-----------------------------------



## Product recommendations

### Accessories



CASA30300  
Eycasa Mobile Handset



CASA30100  
Eycasa Video Door Station



CASA30400  
Eycasa Family Care Camera



CASA30500  
Eycasa Outdoor Camera



CASA30150  
Battery Set




- Wireless Outdoor Camera for security day & night
- Family Care Camera as baby monitor with video image
- Perfect care for babies, infants and senior citizens



Eycasa provides home security in a completely new dimension. At the point common intercom systems reach their limits Eycasa leads its triumphs: up to 3 additional cameras serve to completely protect the whole object from front door, backdoor, garage, cellar up to the nursery. Door Intercom and Base Station communicate via radio transmission which offers the possibility to simply set up Eycasa in existing buildings – without running cables. Besides using the

Video Door Station the system can be operated with up to 3 mobile handsets – useful for the whole family thanks to its pocket size. Moreover, the FamilyCare Camera allows a reliable attendance to and care of children and elderly people via video and audio (baby monitor + video signal via mobile handset).

## Stickers included in

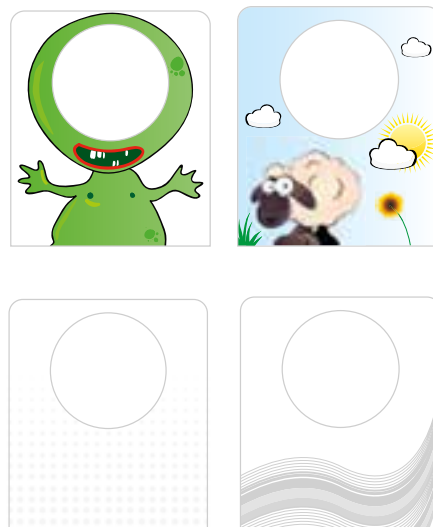



## Article number CASA30300

<b>Description</b>	<b>Eycasa Mobile Handset</b>
<b>Connectable products</b>	Eycasa Main Unit
<b>Resolution modes</b>	320 x 240 @ 1 fps/160 x 120 @ 5 fps
<b>Local functions</b>	Live view on alarm, alarm lists, door intercom function, door opener
<b>Battery power</b>	3 days standby, 250 minutes talk time
<b>Battery type</b>	Integrated 1200 mAh Li-Ion accumulator
<b>Fastener</b>	Charging cradle incl. wall bracket
<b>Adjustable alarm tone</b>	5 ring tones
<b>Event log</b>	25
<b>Audio</b>	Loud speaker with hands-free function, 3.5mm stereo plug
<b>Radio range</b>	30 m
<b>Monitor type</b>	3.2" LCD touch screen
<b>Mounting place</b>	Interior, surroundings fitted for optimum transmission
<b>Power supply DC</b>	5 V
<b>Power consumption</b>	250 mA
<b>Dimensions (W x H x D)</b>	65 x 125 x 20 mm

<b>Scope of delivery</b>	Eycasa Mobile Handset incl. accumulator • Power supply incl. EU, AUS and UK adapter • Charging station • Mounting material • Quick guide
--------------------------	--

<b>Price excl. VAT</b>	<b>Conditions for dealers on request</b>
------------------------	--

## Article number CASA30400

<b>Description</b>	<b>Eycasa Family Care Camera</b>
<b>Connectable products</b>	Eycasa Main Unit
<b>Resolution</b>	640 x 480
<b>Image sensor</b>	1/4" CMOS sensor
<b>Frame rate</b>	20 fps
<b>Focal length</b>	4.3 mm
<b>Horizontal angle of view</b>	48°
<b>IR range</b>	3 m
<b>Alarming</b>	Audiotrigger signal to base station
<b>Audio</b>	Built-in loud speaker and microphone
<b>Battery power</b>	Approx. 5 days
<b>Battery type</b>	Integrated 1200 mAh Li-Ion accumulator
<b>Operating mode</b>	Permanent power supply or battery mode
<b>Radio range</b>	30 m
<b>Power supply DC</b>	5 V
<b>Power consumption</b>	400 mA
<b>Dimensions (W x H x D)</b>	70 x 115 x 25 mm

<b>Scope of delivery</b>	Eycasa Family Care Camera • Mounting material • Swan neck with clip • Quick guide • Power supply incl. EU, AUS and UK adapter
--------------------------	---

<b>Price excl. VAT</b>	<b>Conditions for dealers on request</b>
------------------------	--

## Article number CASA30500

<b>Description</b>	<b>Eycasa Outdoor camera</b>
<b>Connectable products</b>	Eycasa Main Unit
<b>Resolution</b>	640 x 480
<b>Image sensor</b>	1/4" CMOS sensor
<b>Frame rate</b>	20 fps
<b>Focal length</b>	3.6 mm
<b>Horizontal angle of view</b>	56°
<b>IR LEDs</b>	27
<b>IR range</b>	8 m
<b>Removable IR cut filter</b>	Yes
<b>Alarming</b>	PIR sensor alarm at the base station
<b>PIR angle of view</b>	60°
<b>PIR range</b>	5 m
<b>Radio range</b>	30 m
<b>Protection class IP</b>	66
<b>Power supply DC</b>	5 V
<b>Power consumption</b>	550 mA
<b>Dimensions (W x H x D)</b>	70 x 65 x 105 mm

<b>Scope of delivery</b>	Outdoor camera • Camera bracket • Mounting material • Power supply incl. EU, AUS and UK adapter • Quick guide
--------------------------	---

<b>Price excl. VAT</b>	<b>Conditions for dealers on request</b>
------------------------	--