




Part Number : [5024302230](#)

Product Description : SlimStack Board-to-Board Plug, 0.40mm Pitch, Surface Mount, Dual Row, Vertical Stacking, 1.00mm Stacking Height, with Solder Tabs, with Vacuum Tape, 22 Circuits

Series Number : 502430

Status : Active

Product Category : Board-to-Board Connectors

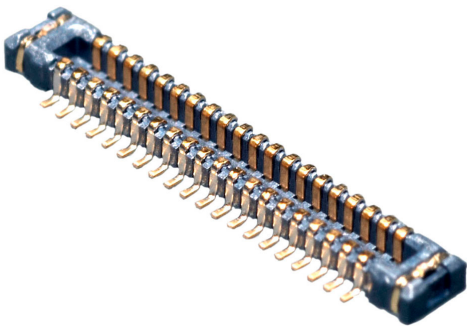

Documents & Resources

Drawings

[5024302230_sd.pdf](#)

3D Models and Design Files

[5024302230_stp.zip](#)

Specifications

[5024309200-SPK-200.pdf](#)

[5024260000-000.pdf](#)

Product Environment Compliance

Compliance

GADSL/IMDS	Not Relevant
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)7663-DC (21 Jan 2025)
EU RoHS	Compliant per EU 2015/863

[Multiple Part Product Compliance Statements](#)

- Eu RoHS
- REACH SVHC
- Low-Halogen

[Multiple Part Industry Compliance Documents](#)

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

Part Details

General

Status	Active
Category	Board-to-Board Connectors
Series	502430
Description	SlimStack Board-to-Board Plug, 0.40mm Pitch, Surface Mount, Dual Row, Vertical Stacking, 1.00mm Stacking Height, with Solder Tabs, with Vacuum Tape, 22 Circuits
Series Name	0.4, T10
Application	Board-to-Board, Signal
Component Type	PCB Header
Product Name	SlimStack
UPC	883906053659

Electrical

Current - Maximum per Contact	0.3A
Voltage - Maximum	50V AC (RMS)/DC

Physical

Breakaway	No
Circuits (Loaded)	22
Circuits (maximum)	22
Color - Resin	Black
Durability (mating cycles max)	30
Glow-Wire Capable	No
Mated Height	1.00mm
Mated Width	2.60mm
Material - Metal	Phosphor Bronze

Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	12.907/mg
Number of Rows	2
Orientation	Vertical
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Retention	Yes
Pitch - Mating Interface	0.40mm
Pitch - Termination Interface	0.40mm
Polarized to Mating Part	No
Polarized to PCB	No
Temperature Range - Operating	-40° to +85°C
Termination Interface Style	Surface Mount

Mates With / Use With

Mates with Part(s)

Description	Part Number
0.40mm Pitch SlimStack Board-to-Board Vertical Receptacles	<u>502426</u>