

Data sheet | Item number: 858-150


Basic relay; Nominal input voltage: 24 VDC; 4 changeover contacts; Limiting continuous current: 5 A; with manual operation; Module width: 22 mm; Module height: 25 mm

www.wago.com/858-150



Similar to picture



RoHS Compliant

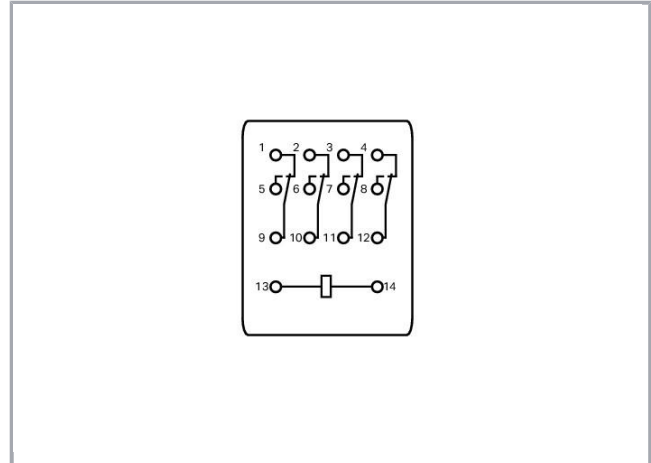

Subject to changes.

WAGO Kontakttechnik GmbH & Co. KG
Hansastr. 27
32423 Minden
Phone: +49571 887-0 | Fax: +49571 887-169
Email: info.de@wago.com | Web: www.wago.com

Do you have any questions about our products?
We are always happy to take your call at +49 (571) 887-44222.

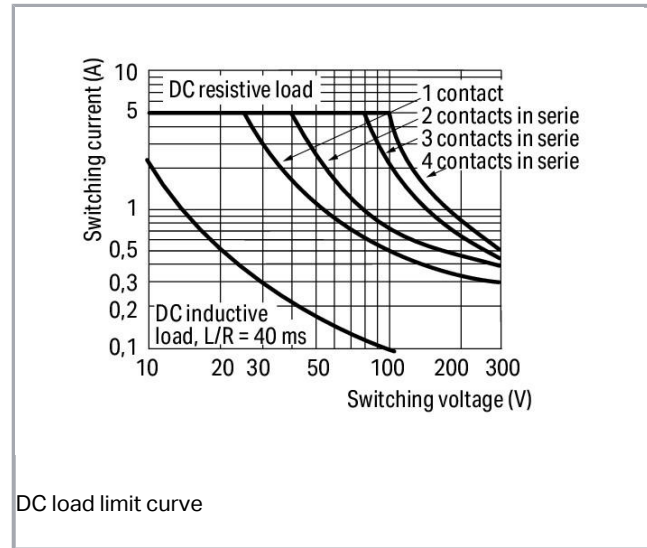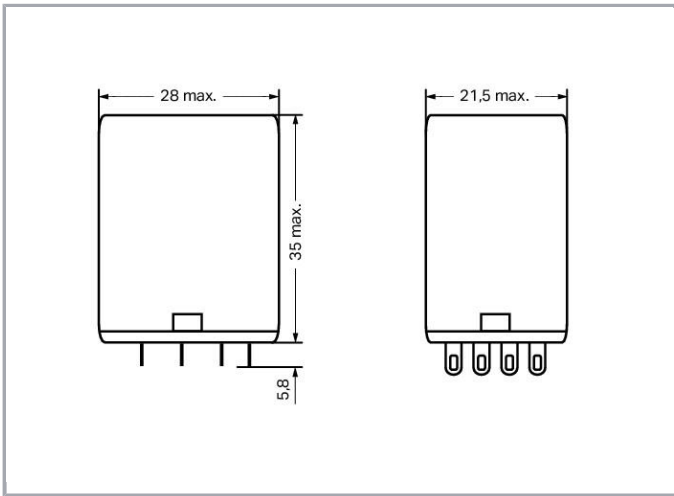

Data
Technical Data

Control circuit

Nominal input voltage U_N	DC 24 V
Nominal input current at U_N	36.9 mA

Load circuit:

Number of changeover/switchover contacts	4
Contact material (relay)	AgCe
Limiting continuous current	5 A
Max. make current (resistive)	(AC) 15 A / 4 s
Max. switching voltage	AC 250 V
Max. switching power (resistive)	AC 1250 VA; DC see load limit curve
Recommended minimum load	12 V / 100 mA
Pull-in time (typ.)	25 ms
Drop-out time (typ.)	25 ms
Bounce time (typ.)	4 ms
Electrical life (N.O.; resistive load; 23 °C)	100 x 10 ³ switching operations
Mechanical life	20 x 10 ⁶ switching operations

Subject to changes.

Signaling

Status indication	LED red Mechanical
-------------------	-----------------------

Safety and protection:

Dielectric strength, control/load circuit (AC, 1 min)	1.5 kVrms
Dielectric strength open contact (AC, 1 min)	1 kVrms
Dielectric strength, load/load circuit (AC, 1 min)	1.5 kVrms
Protection class	IP20

Geometrical Data

Width	21.5 mm / 0.846 inch
Height from the surface	35 mm / 1.378 inch
Depth	28 mm / 1.102 inch

Mechanical data

Type of mounting	Pluggable module
------------------	------------------

Material Data

Weight	35.2 g
--------	--------

Environmental Requirements

Surrounding air (operating) temperature at U_N	-25 ... 70 °C
Surrounding air (storage) temperature	-40 ... 80 °C

Standards and specifications

Standards/specifications	EN 61810-1
--------------------------	------------

Commercial data

Product Group	6 (Interface Electronics)
Packaging type	BOX
Country of origin	CN
GTIN	4055143531931
Customs Tariff No.	85364190890

Subject to changes.

Compatible products

General accessories



Item no.: 858-100

Relay socket; 4 changeover contacts

www.wago.com/858-100

Downloads

Documentation

Bid Text

858-150 doc - Datei	2017-11-29	doc 27.1 kB	Download
------------------------	------------	----------------	----------

858-150 X81 - Datei	2019-2-19	xml 3.9 kB	Download
------------------------	-----------	---------------	----------

Additional Information

Disposal; Electrical and electronic equipment, Packaging	V 1.0.0	pdf 265.8 kB	Download
--	---------	-----------------	----------

CAD/CAE-Data

CAE data

EPLAN Data Portal 858-150	Download
---------------------------	----------

WSCAD Universe 858-150	Download
------------------------	----------

Installation Notes

Subject to changes.