



SITOR cylindrical fuse link, 22x127 mm, 40 A, gR, Un AC: 1500 V, Un DC: 1000 V

Model		
product brand name	SETRON	
product designation	SITOR cylindrical fuse link	
General technical data		
operating class of the fuse link	gR	
type of voltage of the operating voltage	AC	
supply voltage at DC	1 000 V	
Main circuit		
operational current rated value	40 A	
Product details		
product component striker	No	
Mechanical Design		
mounting position	Any, preferably vertical	
net weight	104 g	
Approvals Certificates		
General Product Approval	other	Environment




[Confirmation](#)

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information	
Information on the packaging	https://support.industry.siemens.com/cs/ww/en/view/109813875
Information- and Downloadcenter (Catalogs, Brochures,...)	http://www.siemens.com/lowvoltage/catalogs
Industry Mall (Online ordering system)	https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NC2340-0MK
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)	https://support.industry.siemens.com/cs/ww/en/ps/3NC2340-0MK
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)	http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NC2340-0MK
CAX-Online-Generator	http://www.siemens.com/cax
Tender specifications	http://www.siemens.com/specifications

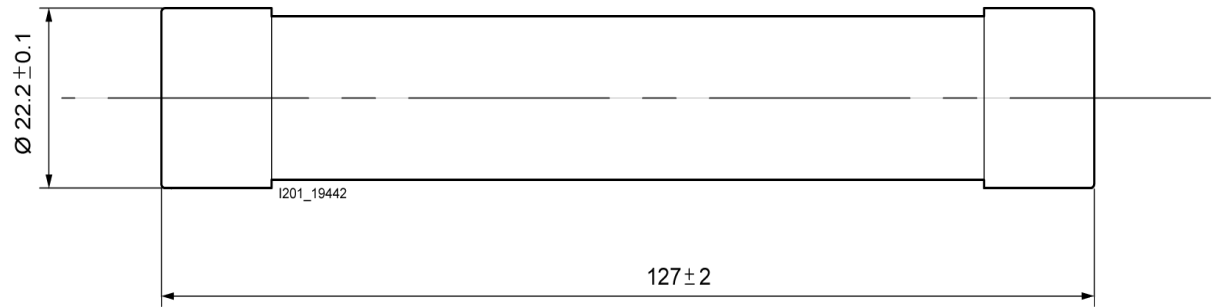

last modified:

4/11/2025 

