

Product Datasheet

Rechargeable

eneloop AA



BK-3MCDE




IEC Dimensions (mm)		
Dimension	Maximum	Minimum
A	50,4	
B	14,35	


Name	BK-3MCDE
Size	AA
Type	NiMH rechargeable
Nominal Voltage	1.2 V
Made in	Japan
Average weight	28 g
Capacity (minimum)	2000 mAh
Ambient temp. charge	0°C - 40°C
Ambient temp. discharge	-20°C - 50°C
Internal impedance (after discharge to E.V.=1.0V)	Approx. 25mΩ (at 1000Hz)

Typical characteristics

Charge

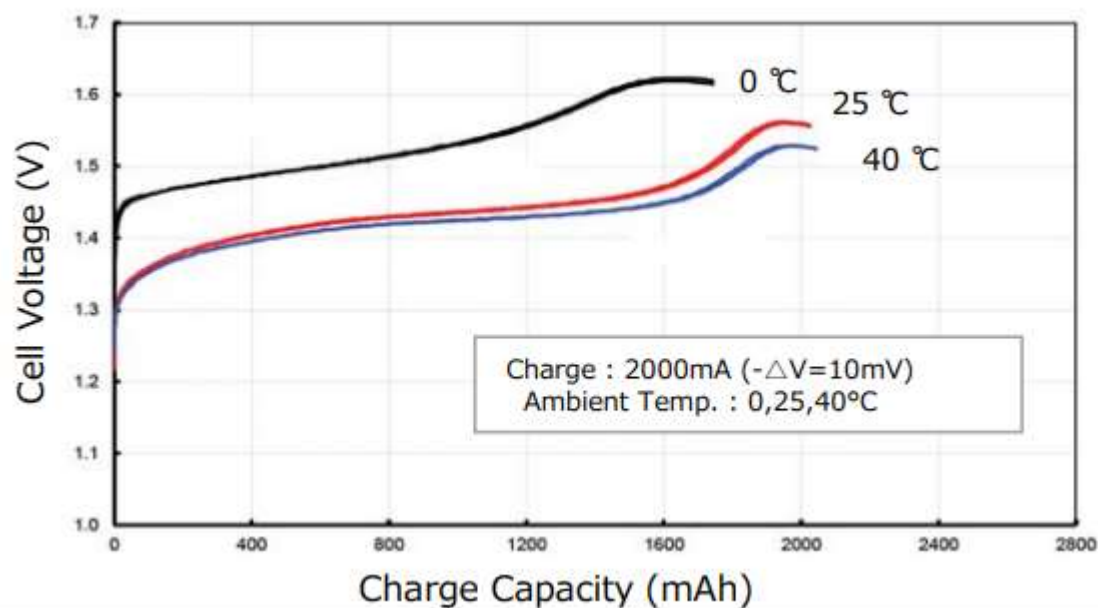

Discharge

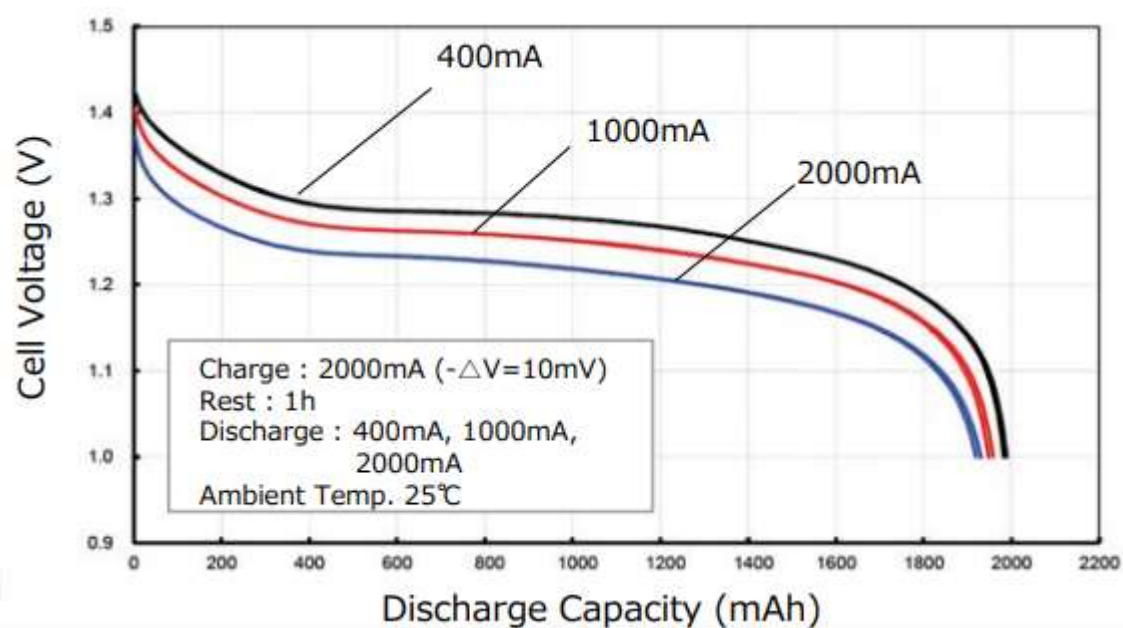

Copyright© Advance Power Solutions NV 2022 — All rights reserved. The information contained herein is believed to be correct. However no warranty is made, either expressed or implied regarding the accuracy or the results to be obtained from the use of such information. Test results are according to IEC conditions. Capacities of batteries are depending on drain, temperature and cut-off voltage. Data are subject to change without prior notification.
October 2022.