


Part Number: 1904X3ZX

Type	Size	Rating	Description
LED	M8	24VAC/DC	LED Panel Indicator

Dimensions(mm)

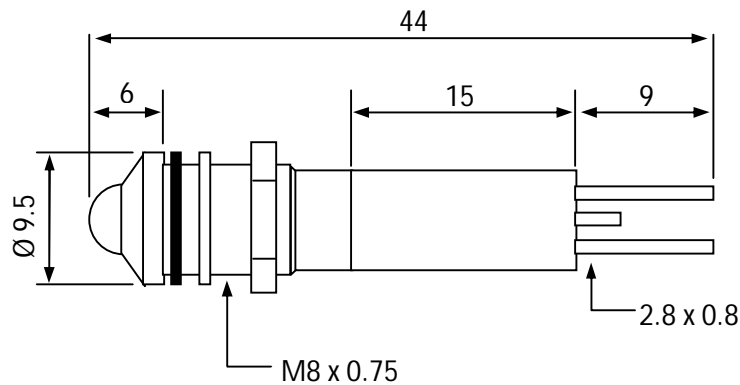

Part #	Colour	Current(mA)	Intensity(mcd)
1904X3Z3	Red	9/18	72
1904X3Z1	Green	9/18	29
1904X3Z2	Yellow	9/18	29
1904X3Z7	Blue	9/18	54

Notes:

- 1 Electrical & optical data are measured at an ambient temperature of 25°C
- 2 Luminous intensity at DC
- 3 Storage temperature -25 °C to +80°C
- 4 Application temperature -20 °C to +60°C
- 5 Voltage tolerance  $\pm 10\%$
- 6 Due to component tolerances, colour temperature variations may be observed
- 7 The terminals are not qualified for soldering
- 8 Degree of protection IP67 when used with the supplied gasket
- 9 The plastic(polycarbonate) has limited chemical resistance
- 10 RoHS & REACH SVHC compliant