


# Square D NEMA Style Combination Motor Starters

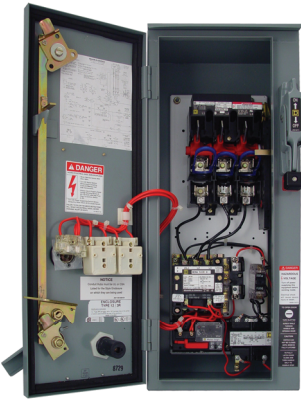

Customized product, competitively priced, and in stock now!

- Long-lasting, energy-efficient Red-ON and/or Green-OFF LED pilot lights
- Specially designed, pliable “foam-in-place” cabinet seals
- Available with Electronic Motor Circuit Protector (MCP) circuit breakers or fusible/non-fusible disconnect switch
- NEMA® Type 1, 12/3R enclosure
- HOA selector switch
- Up to two Normally Open (N.O.) and two Normally Closed (N.C.) aux contacts
- 120 V separate control voltage
- Separate control voltage interlock

## Disconnect Switch Combination Starters

If your customer needs:						Pick from these starters:	
NEMA Size	Fuse Clip Size	Voltage (VAC)	Horsepower	Overload Relay	Current Range	Combination Starters	UPC/EAN
0 or 1	30 A	208 or 240	3 to 5	Melting Alloy	n/a	8538SCASP1	785901685043
1	60 A	208 or 240	5 to 7.5	Melting Alloy	n/a	8538SCASP2	785901863137
0 or 1	30 A	480 or 600	5 to 10	Melting Alloy	n/a	8538SCASP3	785901828457
1 or 2	60 A	208 or 240	7.5 to 10 (208) 7.5 to 15 (240)	Melting Alloy	n/a	8538SDASP1	785901692188
1 or 2	30 A	480 or 600	10 to 15	Melting Alloy	n/a	8538SDASP2	785901692461
2	60 A	480 or 600	15 to 25	Melting Alloy	n/a	8538SDASP3	785901915447
0 or 1	30 A	208 or 240	0.75 to 2	Motor Logic	3 - 9 FLA	8538SCASP4	785901169536
1	60 A	208 or 240	3 to 7.5	Motor Logic	9 - 27 FLA	8538SCASP5	785901656050
0 or 1	30 A	480 or 600	5 to 10	Motor Logic	6 - 18 FLA	8538SCASP6	785901875543
1 or 2	60 A	208 or 240	5 to 10 (208) 5 to 15 (240)	Motor Logic	15 - 45 FLA	8538SDASP4	785901876427
1 or 2	30 A	480 or 600	7.5 to 15	Motor Logic	9 - 27 FLA	8538SDASP5	785901908258
2	60 A	480 or 600	15 to 25	Motor Logic	15 - 45 FLA	8538SDASP6	785901908524

## MCP Circuit Breaker Combination Starters\*

If you need:						Pick from these starters:	
NEMA Size	Breaker Size	Voltage (VAC)	Horsepower	Overload Relay	Current Range	Combination Starters	UPC/EAN
1	30 A	240 or 480	0.25 to 7.5 (240) 0.25 to 10 (480)	Melting Alloy	n/a	8539SCASP3	785901910602
2	30 A	240 or 480	1.5 to 7.5 (240) 5 to 15 (480)	Melting Alloy	n/a	8539SDASP2	785901910749
2	50 A	240 or 480	7.5 to 10 (240) 15 to 25 (480)	Melting Alloy	n/a	8539SDASP3	785901955528
1	30 A	240 or 480	0.75 to 2 (240) 1.5 to 5 (480)	Motor Logic	3 - 9 FLA	8539SCASP6	785901955764
2	30 A	240 or 480	3 to 7.5 (240) 7.5 to 15 (480)	Motor Logic	9 - 27 FLA	8539SDASP5	785901973775
2	50 A	240 or 480	5 to 10 (240) 15 to 25 (480)	Motor Logic	15 - 45 FLA	8539SDASP6	785901973980

\* Horsepower ratings also available at 208 and 600 VAC



Want to learn more?  
Scan this QR code with  
your smartphone for  
an informative video  
about Square D NEMA Combination  
Motor Starters.



by Schneider Electric