


1748-BH

Nylon cable ties with eyelets, natural colour

CE

Material: polyamide PA 6.6
 Self-extinguishing class: UL 94-V2
 Working temperature: -40 °C ÷ +85 °C
 Minimum installation temperature: -10 °C
 Resistance to chemicals: Good resistance to bases, oils, greases, chloride solvents. Limited resistance to acids. Not resistant to phenols
 Reference standards: EN 62275:2015-02
 Classification: type 1 (EN); type 21 (UL)

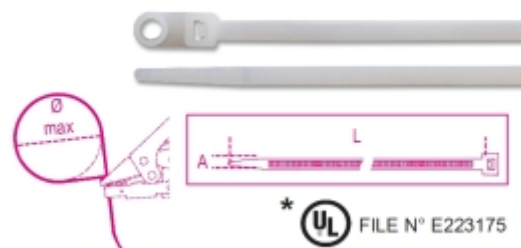

		art.	A mm	L mm	Ø MAX mm	F MAX N
	BMBH1125	BMBH1125	2.5	110	19.0	80
*	BMBH2048	BMBH2048	4.8	200	49.8	230
*	BMBH3076	BMBH3076	7.6	305	78.7	550