

TECHNICAL CHARACTERISTICS

MATERIAL  
 INSULATOR: NYLON 66  
 FLAMABILITY RATING: UL94-V0  
 COLOR: WHITE  
 PITCH: 2.00MM

ENVIRONMENTAL  
 OPERATING TEMPERATURE: -25°C UP TO 85°C  
 COMPLIANCE: LEAD FREE AND ROHS

ELECTRICAL  
 INSULATOR RESISTANCE: >1000 MOHM  
 DIELECTRIC WITHSTANDING VOLTAGE: 800V AC/MN

STANDARD  
 CERTIFIED: E323964

PACKAGING  
 BAG


DIMENSION  
 A = 2.00 x (NB. PIN - 1)  
 B = 2.00 x (NB. PIN) + 1.80

A

B

C

RoHS Compliant			
G			
F	26-MAY-14	OPE TEMPERATURE	QL
E	06-AUG-13	CHARACTERISTIC	QL
D	17-NOV-09	STANDARD	JP
C	28-OCT-09	W. VOLTAGE	JP
B	02-JUN-09	C DIMENSION	JP
A	01-NOV-08	PDF	CH
REV	DATE	FILE	BY

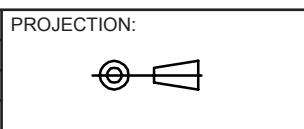

GENERAL TOLERANCE  
 .X = +/- 0.2  
 .XX = +/- 0.15



APPROVAL: RJ

UNIT: MM  
 SCALE:  
 SHEET: 1/1  
 DRAW: JERRY CHEN

DESCRIPTION: 2.00 MM FEMALE TERMINAL HOUSING  
 WERI PART NO: 6200xx113322

SIZE  
**A4**

D