




LED Special Ba15d T15X36 48V AC/DC 1W 80lm (9W) 827

Article number: 145222

BAI LED Compact Ba15d Tube 15x36mm 48V 70mA 0.07A 1W AC=1W DC=0.33W 2700K 80lm (9W) 20000h Indication- and signalling lamp

Compact and powerful LED indication & signaling lamp to replace the conventional miniature lamps. Ambient temperature: -20°C to +40°C. Not suitable for signaling columns.

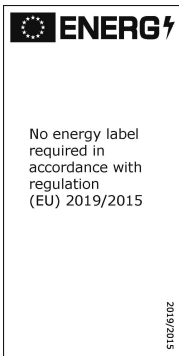

General ETIM properties

ETIM group	Lamps
ETIM class	Indication- and signalling lamp
Name	LED Special Ba15d T15X36 48V AC/DC 1W 80lm (9W) 827
Brand	Bailey
Productseries	LED Special
Producttype	Tube Ba15d

ETIM specifications

Socket	BA15d
Lamp voltage [V]	48 - 48
Nominal current [mA]	7
Lamp power [W]	0.33 - 1
Diameter [mm]	15
Total length [mm]	36
Lamp shape	Tube, single-ended
Technology	LED
Luminous flux [lm]	80
Halogen	No
Krypton	No
Xenon	No
Colour	White
Colour temperature [K]	2700
Suitable for torches	No
Suitable for pointer	No
Suitable for round flashing luminaire	No
Average nominal lifetime [h]	20000
Energy efficiency class according to EU regulation 2019/2015	Not required