


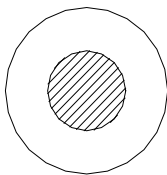

Product Name:	UL1180 22AWG
Product Discription:	UL1180 22AWG
Specification No.:	
Customer's Name:	

Description					Construction							
Rated Voltage:		300Vac(UL allows 600V for electronic use only).			Conductor		Stranded Sliver plated copper					
Rated Temperature:		200℃,Optional - 80 ℃ Oil, Gasoline Resistant.			Size(AWG)		22					
Reference Standard:		UL758			Construction(±0.008mm)		19/0.16					
Cross Section					Stranded Dia.(mm)Ref.		0.762					
					Insulation Material		PTFE					
					Insulation Color		ANY COLOR					
					Ave Thickness(mm)		0.33					
					Insulation Dia.(±0.10mm)		1.52					
Marking					Remark:							
No marking on the cable jacket, have UL label on the Reel.					8740236 Red		8740245 Blue		8740258 Grey		8740267 Violet	
					8740239 Black		8740248 White		8740251 Yellow			
					8740232 Brown		8740242 Green		8740254 Orange			
Applications					Characteristics					Customer Approve		
For internal wiring of electronic and electrical equipment					Test Item			Standard Value			Seal & Stamp	
					Test Material			PTFE(ROHS)				
					Insulation resistance(20℃ MΩ*m			1000				
					Vol. Tesr(AC.V.60S) (V)			2000				
					Flammability Test			Horizontal flame				
Revisions					Max.DC Resistance(20℃ Ω/km)			48.5(MAX)			Signature: Date:	
Version	Description	Drawn by	Approved by	Date								
0	New document issue	Danniel	Jason	24/04/2015								