
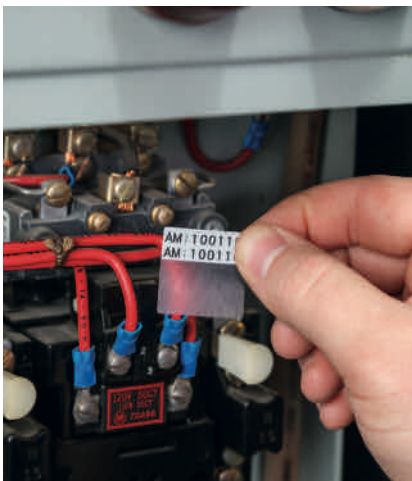
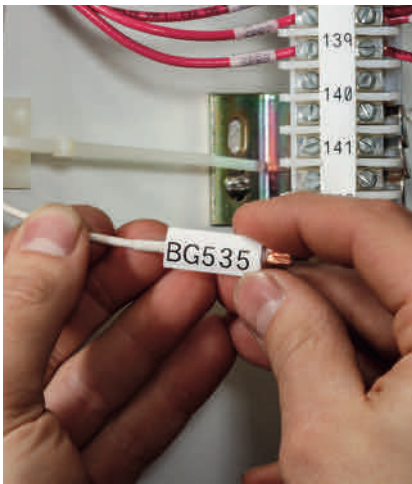


# BMP™61 Label Printer

## Performance that matches your own

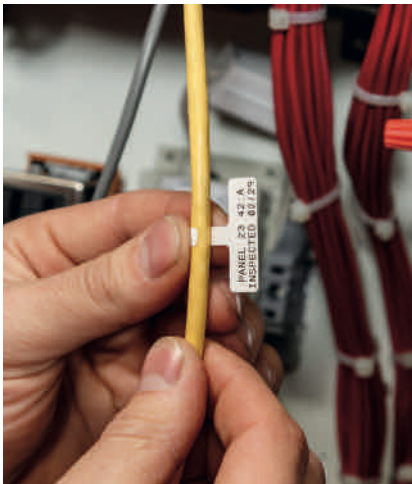

Designed with molded rubber bumpers and a vivid colour touch screen with on screen indicators, the rugged and reliable BMP™ 61 Label Printer will be your trusted identification companion of choice, all day, every day, for years to come.

The BMP™61 Label Printer offers great performance that matches your own. It is portable, fast and can handle a lot of identification challenges thanks to its wireless connectivity and a wide range of durable labels to print on.

### Data management versatility

The printer features on-board list management. Use the printer's USB-ports to copy large lists of label design from a computer.

The rugged, portable BMP61 is also available in a wifi-enabled version compatible with the LabelMark label creation software and Brady mobile apps. Simply create or send label designs from a smart phone to the printer for extremely fast and easy label creation on the job.

### High Performance

With its 33.8mm/sec print speed, predefined label templates, label creation wizards, built-in label cutter and data serialization options, the BMP61 Label Printer is a durable partner in the field.

### Printer

Article No.	Order Ref.
146229	BMP61
146226	BMP61-W
146230	BMP61-QWERTY-EU
146227	BMP61-QWERTY-EU-W
148638	BMP61-AZERTY-EU
146231	BMP61-AZERTY-EU-W
196453	BMP61-QWERTY-UK
196454	BMP61-QWERTY-UK-W
148637	BMP61-QWERTZ-EU
146224	BMP61-QWERTZ-EU-W
146223	BMP61-CYRILLIC

### Kits\*\*\*

Article No.	Order Ref.
196455	BMP61-AZERTY-EU-EL*
196456	BMP61-AZERTY-EU-DA**
196457	BMP61-QWERTY-EU-EL*
196458	BMP61-QWERTY-EU-DA**
196461	BMP61-QWERTZ-EU-EL*
196462	BMP61-QWERTZ-EU-DA**
196465	BMP61-CYRILLIC-EL*
196466	BMP61-CYRILLIC-DA**

\*This Electrical kit ships in a hard case holding a BMP61 Printer, a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423, PTL-21-427, PTL-31-499, PSPT-187-1-YL, M61-R-4310, M61-R6010, a LabelMark 6 Standard CD and a BMP61 Magnet.

\*\*This Datacomm kit ships in a hard case holding a BMP61 Printer, a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423, PTL-31-427, PTL-8-422, PTL-12-109, M61-R4310, M61-R6010, a LabelMark 6 Standard CD and a BMP61 Magnet.

\*\*\*Also available with US and UK power charger.

### Accessories

Article No.	Description
018556	Printer cleaning kit
103788	USB Cable
146221	Magnet for BMP61

## Prints in 300dpi multiple qualitative high-performance materials

The rugged, thermal transfer BMP61 Label Printer can print on a wide range of durable die-cut, continuous & custom labels including sleeves, self-laminating labels and raised profile labels up to 48,76mm wide.



Every BMP61 label and ribbon is automatically recognised and auto-calibrated by the printer. The printer's colour touch screen displays which label material is currently installed and how many labels, how much ink and how much battery is left for maximum ease of use.

Customise your labels in personalised shapes or dimensions, in specific colours or layouts or with your logo already present on the label. Simply insert the custom labels in your BMP61 Label Printer's to solve your identification challenges.



Your Brady Distributor

[www.bradyeurope.com/BMP61](http://www.bradyeurope.com/BMP61)

22/06/2016  
EUR-M-831-EN

PRINTER	
Includes	This printer ships in a hard case holding a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423 and an M61-R6010 ribbon.
Weight (kg)	1.5
Size W x D x L (mm)	107 x 106 x 328
Keyboard Type	QWERTY, QWERTZ, AZERTY, CYRILLIC
Min. Label Width	5.08 mm
Max. Label Width	50.80 mm
Internal Memory Capacity	512MB of FLASH storage and 512MB of RAM
Warranty	2 years

MATERIALS SUPPORTED	
Materials Supported	600+ standard parts: continuous tapes, die cut and bulk label rolls, custom made labels and tapes.

FONTS/GRAPHICS/SYMBOLOGIES	
Bar Code Type	Code 39 and 128, other via software
Text Sizes (pt)	4 to 174pt + autosizing
Built-in Fonts	Brady Alpine, Brady Fixed Width

SOFTWARE & CONNECTIVITY	
Connectivity Options	USB 2.0, USB Flash Drive, WIFI
Software Compatibility	Labelmark 6.0, Brady Mobile Apps

POWER SUPPLY	
Battery Type	Rechargeable NiMH Battery
Power Supply	AC Power

COMPLIANCE	
Approval/Compliance	UL; cUL; CE; RoHS; EAC

**i**

Consult the video of the BMP61 Label Printer on [www.bradyeurope.com/BMP61](http://www.bradyeurope.com/BMP61)



### Brady EMEA Locations

Africa	+27 11 704 3295	Middle East	+971 4881 2524
Benelux	+32 (0) 52 45 78 11	Norway	+47 70 13 40 00
Central & Eastern Europe	+421 2 3300 4800	Romania	+40 21 202 3032
Denmark	+4566 14 44 00	Russia	+7 495 225 93 62
France	+33 (0) 3 20 76 94 48	Spain & Portugal	+34 900 902 993
Germany	+49 (0) 6103 7598 660	Sweden	+46 (0) 8 590 057 30
Hungary	+36 23 500 275	Turkey	+90 212 264 02 20
Italy	+39 02 26 00 00 22	UK & Ireland	+44 (0) 1295 228 288