



Go To Step Search™ Screen

320560 -- *1 of 1 products*


Terminals and Splices

Ring and Spade Tongue Terminals

General **INFO**

Sales **INFO**

Customer Drawings
SPECIFICATIONS

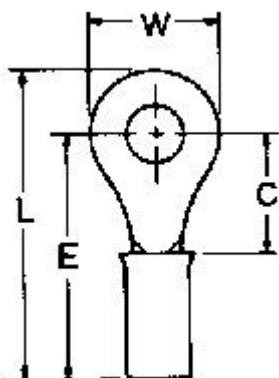

Line art represents typical product only.

<i>Searchable Features:</i>	
Terminal Shape	Ring Tongue
Body Style	PIDG
Receptacle Style	Straight
Barrel Type	Closed Barrel
Wire/Cable Type	Regular Wire
Wire Range	16-14 [1.25-2.00 ²] AWG [mm]
Wire Range (CMA)	2,050-5,180
Insulation	Yes
Insulation Support	Insulation Support
Insulation Diameter	.150 [3.81] Max. in. [mm]
Stud Size	8 [M4]
Stud Diameter	.164 [4.16] in. [mm]
Shape	RING-041
Heavy Duty	Standard
Packaging Method	Loose Piece
Material	Copper
Finish	Tin
<i>Other Properties:</i>	
Dim. C	.281 [7.14] Min. in. [mm]
Dim. E	.685 [17.40] Max. in. [mm]
Dim. L	.859 [21.82] Max. in. [mm]
Dim. W	.343 [8.71] in. [mm]
Tongue Material Thickness	.033 [0.84] Max. in. [mm]
Color	Blue
Comment	"C" dimension applies from edge of metal wire barrel to center of stud hole.