

# 0 601 9G4 301 – GDS 18V-200 C

Material number	0 601 9G4 301	0 601 9G4 302	0 601 9G4 370
EAN	3165140977524	3165140977531	3165140977517
1 x Bluetooth Low Energy module GCY 30-4 1 600 A00 R26			✓
1/2 L-BOXX inlay for tool and charger 1 600 A01 CU5	✓	✓	✓
2 x battery ProCORE18V 4.0Ah 1 600 A01 6GC			✓
L-BOXX 136 1 600 A01 2G0	✓		✓
Quick charger GAL 1880 CV 1 600 A00 B8H			✓
Battery voltage	18.0 V	18.0 V	18.0 V
Tool holder	1/2" external square friction ring + pin hole	1/2" external square friction ring + pin hole	1/2" external square friction ring + pin hole
Charging time (80%/100%) approx.			32/51 min [4.0 Ah]




## Technical data

### Technical data

No-load speed	0-3,400 rpm
No-load speed (1st level)	0-1,100 rpm
No-load speed (2nd level)	0-2,300 rpm
No-load speed (3rd level)	0-3,400 rpm
Torque settings	3
Weight excl. battery	1.1 kg
Torque, max.	200 Nm
Impact rate	0-4,200 bpm
Impact rate (1st level)	0-2,300 bpm
Impact rate (2nd level)	0-3,400 bpm
Impact rate (3rd level)	0-4,200 bpm
Tool holder	1/2" external square friction ring + pin hole

### Screw diameter

Screw diameter	M 6 – M 16
----------------	------------

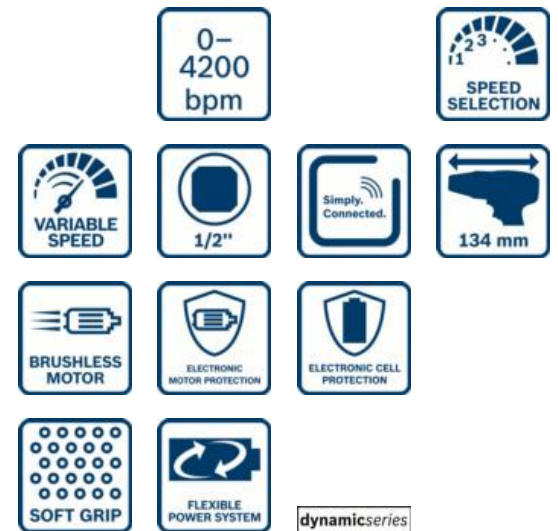

## Sales information

### Positioning

- High power in compact size

### User benefit

- Powerful use even in hard to reach areas thanks to best head length to torque ratio
- Bluetooth Connectivity module for tool feedback, soft start and service information via mobile device
- Longer runtime and lifetime thanks to brushless motor with Electronic Motor Protection (EMP)