

Pre-insulated Female, Male and Piggyback Disconnects



General features


- ✓ Tin-plated brass double crimp "S" version.
- ✓ Tin-plated bronze double crimp "51000" version.
- ✓ 0 Halogen.

"S" double crimp series:

- ✓ Copper sleeve for crimping insulation giving better resistance to vibration.
- ✓ PA insulation sleeve for versions*. PC for versions SQM =. PPSU for other versions.
- ✓ Max. operating temperature: 125°C.




No. 3.2-3.4.02
ECEMA040711

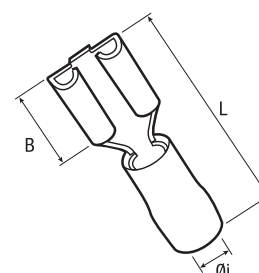

Pre-insulated female disconnects

		Laiton				Brass										Crim- ping pliers
 mm ²	 x100 / Box		 Bulk Packing		 x100 / Box		 Bulk Packing		 Ø mm	Male disconnect		Ø i	B	L		
	Item code	Part no.	Item code	Part no.	Item code	Part no.	Item code	Part no.		Width	Thickness					
● 0.34 - 1.5	7251016	C100SQA2.8-3	7250500	SQA2.8-3*	7261027	C100-51301-3	7260505	51031-3*	3.6	2.8	0.3	1.7	6.5	19.5	TH1	
	7251015	C100SQA2.8-5	7250501	SQA2.8-5*	7261018	C100-51031-2	7260506	51031-2*	3.6	2.8	0.5	1.7	6.5	19.5		
	7251094	C100SQA2.8-8	7250502	SQA2.8-8*	7261030	C100-51031-8	7260508	51031-8*	3.6	2.8	0.8	1.7	6.5	19.5		
	-	-	7251084	SQA4.7-5	-	-	-	-	3.6	4.8	0.5	1.7	6	18.7		
	7251096	C100SQA4.7-8	7251065	SQA4.7-8	-	-	-	-	3.6	4.8	0.8	1.7	6	18.7		
	7251337	C100SQA5N	7251324	SQA-5N	7261447	C100-51081-2	7261442	51081-2	3.6	5	0.8	1.7	7.7	21		
● 1 - 2.5	7251333	C100SQA6.35	7251332	SQA-6.35	7261471	C100-51181-2	7261472	51181-2	3.6	6.3	0.8	1.7	7.7	21	TH2	
	7251097	C100SQB4.7-5	7251085	SQB4.7-5	-	-	-	-	4.3	4.8	0.5	2.4	6	18.7		
	7251098	C100SQB4.7-8	7251067	SQB4.7-8	-	-	-	-	4.3	4.8	0.8	2.4	6	18.7		
	7251338	C100SQB5N	7251344	SQB5N	7261453	C100-51131-2	7261452	51131-2	4.8	5	0.8	2.4	7.7	21		
	7251353	C100SQB6.35	7251352	SQB6.35	7261481	C100-51231-2	7261482	51231-2	4.8	6.3	0.8	2.4	7.7	21		
● 4 - 6	7251382	C100SQC6.35	7251372	SQC6.35	7261512	C100-51661-4J	7261509	51661-4J	6.8	6.3	0.8	3.4	7.7	25	TH3	

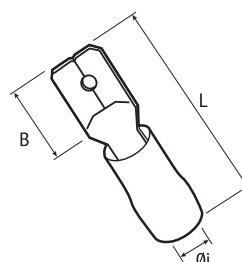

Pre-insulated male and piggyback disconnects

SQM...

mm ²	x100 / Box		Bulk Packing		Male disconnect			Ø i	B	L	Crimping pliers
	Item code	Part no.	Item code	Part no.	Ø mm	Width	Thickness				
● 0.34 - 1.5	7250013	C100SQMA6.35	7250011	SQMA-6.35	3.5	6.3	0.8	1.7	8	20.5	TH1
● 1 - 2.5	7250023	C100SQMB6.35	7250021	SQMB-6.35	4	6.3	0.8	2.4	8	20.5	TH2
● 4 - 6	7250034	C100SQMC6.35	7250031	SQMC-6.35	5.5	6.3	0.8	3.4	8	24.5	TH3



Cable section (mm²)



Packing



Max. Ø cable insulator

* = Polyamide insulator

Unless indicated otherwise, all dimensions are in millimeters.