




HT550R & HT550

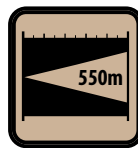


Reactive Distance Sensor

HT550R

The HT550R rechargeable Head torch which offers up to 550 lumens, rechargeable through a mini USB cable. Has a reactive distance sensor to change automatically from spot to flood for close or long distance applications.

- Reactive distance sensor
- Rechargeable
- 550 Lumens
- 550 Metre beam
- 3 light modes: spot beam, wide beam and auto spot to wide
- Adjustable non slip head straps
- Red, green or blue rear warning light options

HT550R	
 169h 7.5h	 0g
	
Run Time	169h 7.5h
Battery	2500mAh Li-ion
Product Weight (kg)	0.283
Boxed Weight (kg)	0.350
Product size (mm)	L85 x D45 x H48 (head) L84 x D40 x H50 (battery pack)
Boxed Size (mm)	W132 x H199
Part No.	NSHT550R

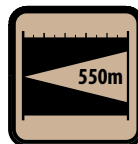



Reactive Distance Sensor

HT550

The HT550 head torch offering 550 lumens has a reactive distance sensor to change automatically from spot to flood for close or long distance applications.

- Reactive distance sensor
- 550 Lumens
- 550 Metre beam
- 3 light modes: spot beam, wide beam and auto - spot to wide
- Adjustable non slip head straps
- Supplied with 4 x AA Alkaline batteries and head strap
- Red, green or blue rear warning light options

HT550	
 169h 7.5h	 0.283kg
Run Time	169h 7.5h
Battery	4 x AA
Product Weight (kg)	0.283
Boxed Weight (kg)	0.350
Product size (mm)	L85 x D45 x H48 (head) L84 x D40 x H50 (battery pack)
Boxed Size (mm)	W132 x H199
Part No.	NSHT550