


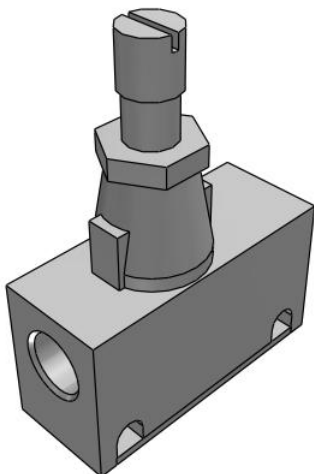


In-line - AS*000 AS2000-N01

Datasheet

General series information

 - Port Size: M3, M5, 1/8, 1/4, 3/8, 1/2
- Operating Pressure Range: 0.05 to 1 MPa.




Flow control valve, adjustable, with reverse free flow


Standard specifications

Size	2 (1/8, 1/4 Basis)
Thread	N (NPT)
Port Size	01 (1/8)
Option	None
Lock Nut	Standard (Hexagon)
Pressure medium	Air
Maximum operating pressure	1 MPa
Minimum operating pressure	0.05 MPa
Proof pressure	1.5 MPa
Maximum ambient temperature	60 °C
Minimum ambient temperature	-5 °C
Weight	0.090 Kg

Dimensions

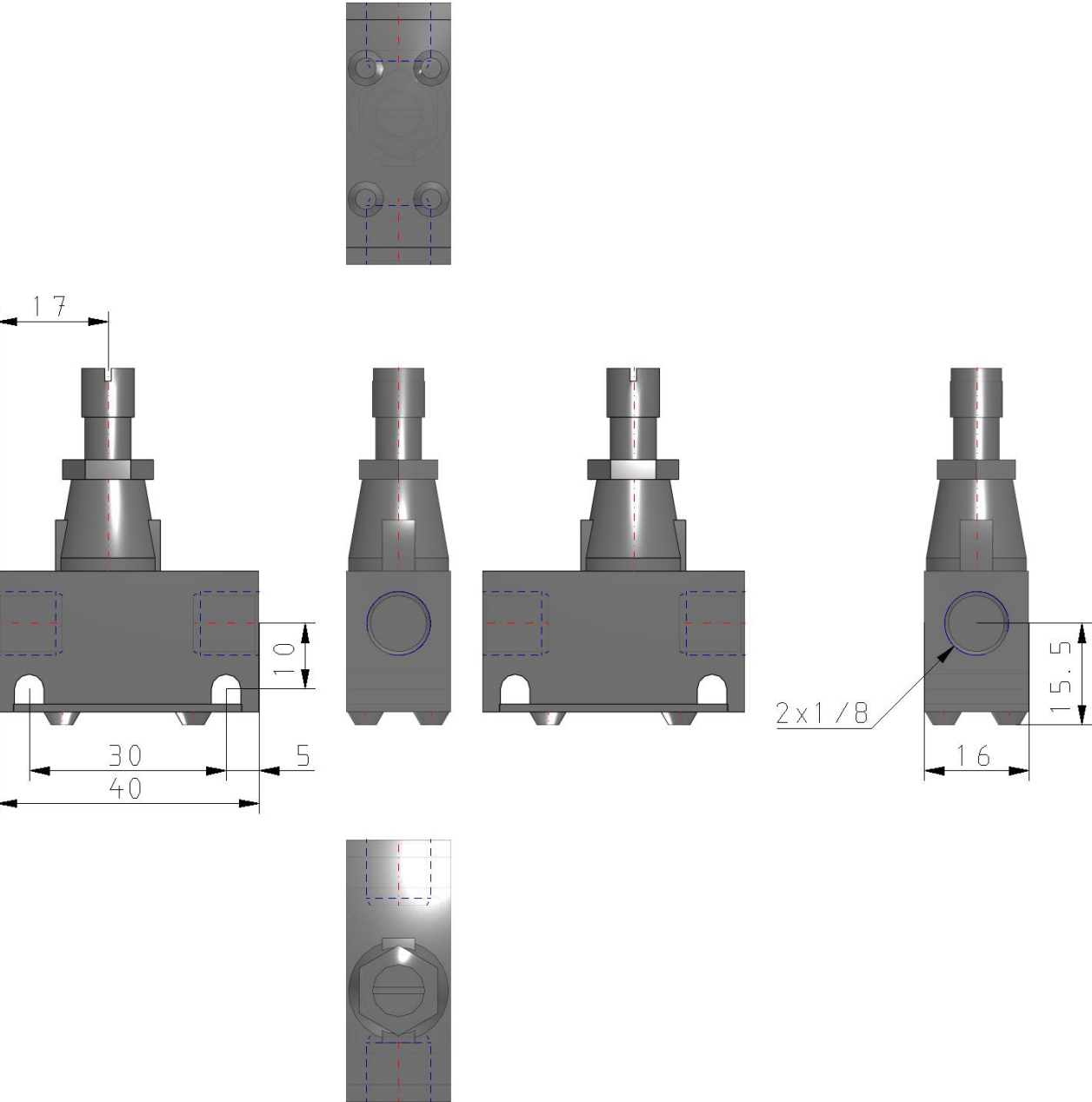

Constructions

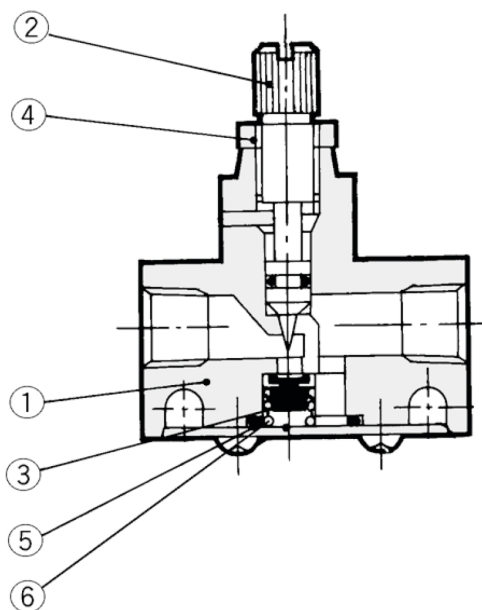

Component Parts

No.	Description	Model	
		AS2000	AS3000
①	Body	Zinc alloy	Aluminum alloy
②	Needle*	Brass	Brass
④	Lock nut*	Brass	Carbon steel
③	Valve		
⑤	O ring		
⑥	Spring		

*Electroless nickel plated

Additional information

Catalogue

[AS_000-A_EU.pdf](#)

Operation manuals

[OM_ASx000_OMA0069EN-E.pdf](#)