

Features

- **Durable, Safe Construction** – Reinforced ABS body is non-conductive, non-sparking, and resistant to chemicals and corrosion, ideal for electrical safety.
- **Enhanced Security** – Supplied with a unique coded brass key and 6-pin cylinder for secure, tamper-resistant locking.
- **Key Retention Safety** – Jack locking mechanism ensures key cannot be removed unless the padlock is properly locked.
- **User-Friendly Grip** – Carved ribbed design allows for easy handling and use, even with gloves.
- **Clear Identification** – Includes “Danger” safety label on the front and a personnel ID label on the back for accountability.
- **Versatile Application** – Designed for both indoor and outdoor use, suitable for a wide range of electrical lockout scenarios.

RS PRO Di-Electric Lockout Padlock with 42 mm Nylon Shackle – Key Different – Yellow

RS Stock No.: 0603268



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *ABS body features carved ribs for easy gripping and handling.*
- *Supplied with a unique coded brass key and 6-pin cylinder for increased security with different locking combinations.*
- *Jack locking key mechanism prevents key release until the shackle is closed and the padlock is locked.*
- *Reinforced ABS body is non-conductive, non-sparking, and resistant to chemicals and corrosion.*
- *Supplied with "Danger" safety label on front and personnel identification label on the back.*
- *Ideal for electrical lockout applications.*
- *Suitable for both indoor and outdoor lockout applications.*
- *Each padlock comes in a box with 1 key.*
- *Equipped with a 42 mm nylon shackle and key different operation.*

General Specifications


Type	Di-electric Lockout Safety Padlock
Material	ABS Body with Nylon Shackle
Colour	Yellow
Package	Individual box & Outer Box

Mechanical Specifications

Padlock Dimensions	42mm X 6mm X 45mm X 43mm X 20mm
Shackle Height	42mm
Shackle Dia	6mm
Body Height	45mm
Body Width	43mm
Body Depth	20mm
Weight	66 Grams

Operation Environment Specifications

Withstand temperature	-20°C to 110°C.
-----------------------	-----------------

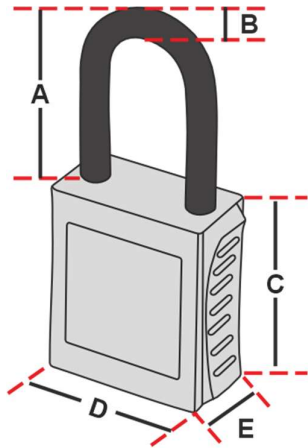

Dimension in mm	
Model	ES-DEL-KD
Shackle Height (A)	42
Shackle Dia (B)	6
Body Height (C)	45
Body Width (D)	43
Body Depth (E)	20