

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0039000220](#)  
**Status:** **Active**  
**Overview:** [Mini-Fit Jr. Power Connectors](#)  
**Description:** [Mini-Fit Male Crimp Terminal, Phosphor Bronze, Gold \(Au\), 18-24 AWG, Bag](#)

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Packaging Specification PK-5556-003 (PDF)</a>
<a href="#">Product Specification PS-5556-001-001 (PDF)</a>	<a href="#">Test Summary TS-5556-002-001 (PDF)</a>
<a href="#">Product Specification PS-5556-002-001 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

**General**

Product Family	Crimp Terminals
Series	<a href="#">5558</a>
Application	Power, Wire-to-Wire
Crimp Quality Equipment	Yes
Overview	<a href="#">Mini-Fit Jr. Power Connectors</a>
Packaging Alternative	<a href="#">39000219 (Reel)</a>
Product Name	Mini-Fit
UPC	800754396356

**Physical**

Durability (mating cycles max)	30
Gender	Male
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Tin
Net Weight	126.914/mg
Packaging Type	Bag
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.30-3.10mm
Wire Size AWG	18, 20, 22, 24
Wire Size mm <sup>2</sup>	N/A

**Electrical**


Current - Maximum per Contact	9.0A
Voltage - Maximum	600V

**Material Info**

Engineering Number	5558PBGSL
--------------------	-----------

**Reference - Drawing Numbers**

Packaging Specification	PK-5556-003
Product Specification	PS-5556-001-001, PS-5556-002-001
Sales Drawing	SD-5558-002-001
Test Summary	TS-5556-002-001

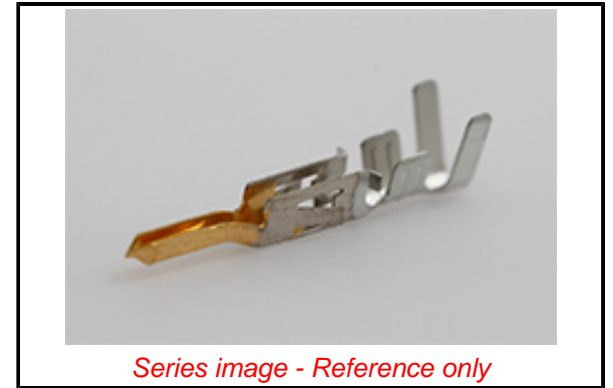

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[5558 Series](#)

**Mates With**

[5556 Mini-Fit Crimp Terminal](#)

**Use With**

[5559 Mini-Fit Jr. Plug Housing](#), [30068 Mini-Fit TPA Plug Housing](#), [42475 Mini-Fit BMI Plug Housing](#)

**Application Tooling | FAQ**

*Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.*

**Global**

**Description**

**Product #**

Extraction Tool	<a href="#">11030044</a>
Hand Crimp Tool for Mini-Fit Jr. Male and Female Crimp Terminals, 18-24 AWG	<a href="#">638190901</a>

**Japan**

**Description**

**Product #**

Handtool (Straight  
Action)

570225500

Hand Crimp Tool

570265000

This document was generated on 08/15/2019

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**