
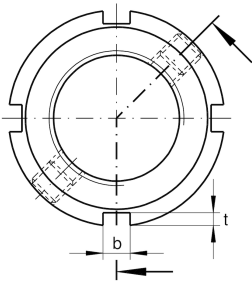


ZMA55/98

Precision locknut

Precision locknuts ZMA, locking pegs, radially arranged, heavy series

Technical information

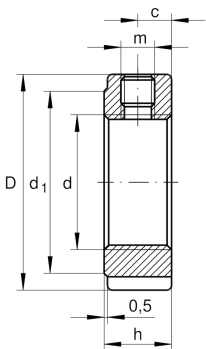

Main Dimensions & Performance Data

d	M55X2	Thread
D	98 mm	Outside diameter
h	32 mm	Height
M _A	15 Nm	Mounting torque set screw
F _{aB}	620,000 N	Breaking load, axial
M _L	150 Nm	Breakawag
M _{AL}	95 Nm	Mounting torque reference
M _M	20.5 kg*cm ²	Mass moment of inertia
≈m	1.263 kg	Weight

Dimensions

d ₁	90 mm	Plant diameter outside
t	3.5 mm	Hight retaining slot
b	8 mm	Width retaining slot
c	16 mm	Distance bore
m	M8	Threaded - threaded pin