

Flexible Magnetic Retrieval Tool

- Flexible Magnetic Retrieval
- Ideal for retrieving items in hard to reach places




Product Number	Length mm	Magnet Diameter/ Outer Diameter mm	Head Length mm	Weight kg	Pull Force kg
MRT505F	505	6/6.5	31	0.10	0.9

Multifunction Telescopic Magnetic Retrieval Tool with Torch and Inspection Mirror

- Multi Function Telescopic Magnetic Retrieval tool with LED and inspection mirror
- Flexible head ideal for hard to reach places
- With added magnetic base can be used as inspection light
- Inspection mirror ideal in confined spaces
- Powerful LED Light (4 x LR44 batteries Included)



Product Number	Length mm	Head Across Flat mm	Head Length mm	Weight kg	Pull Force (Head) kg	Pull Force (Base) kg
MRT582MF	175-582	22.3 (Magnet DIA 19)	58.2	0.132	3.5	5.0

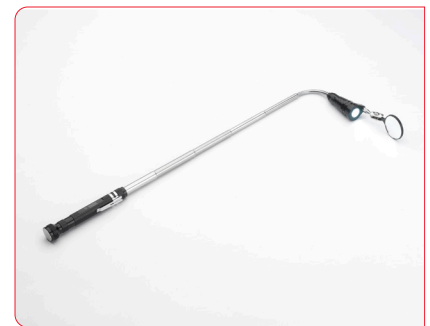

Special Magnetic Retrieval Tool with Torch and Claw

- 62cm flexible length ideal for hard to reach places
- Push button spring steel retrieval claw ideal for non-magnetic pickup
- Powerful LED Light (3 x LR44 batteries included)



Product Number	Length mm	Magnet Diameter/ Outer Diameter mm	Head Length mm	Weight kg	Pull Force kg
MRT625MFF	625	13.5/14.9	75.4	0.15	2.25




Heavy Duty Telescopic Magnetic Retrieval Tool



- Telescopic Magnetic Retrieval tool with over 7kg pick up capacity
- Extends to 77cm
- Anti-slip rubber handle for use in any working environment



Product Number	Length mm	Head Across Flat mm	Head Length mm	Weight kg	Pull Force kg
MRT770	180-770	18.9 (Magnet DIA 16)	18.4	0.88	7

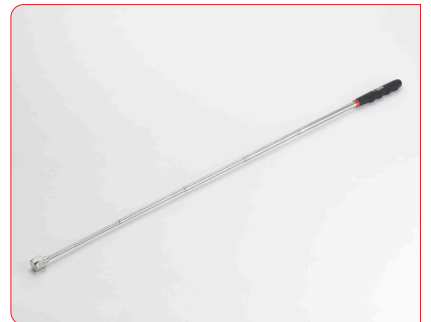

Heavy Duty Telescopic Magnetic Retrieval Tool with Torch

- Extends to 81cm with 3kg magnetic hold
- Perfect for retrieving objects in hard to reach places
- Powerful LED Light (3 x LR44 batteries Included)



Product Number	Length mm	Head Across Flat mm	Head Length mm	Weight kg	Pull Force kg
MRT810T	190-810	17.6 (Magnet DIA 14.5)	33.9	0.08	3

