

Features

- 19" Device Compatibility
- Perforated Ventilation Hole
- 180 Degree Rotatable 3U 19" Rail(Left/Right)
- Breakable Cable Entry Hole
- 5U 19" Horizontal Rail(Left/Right)
- Front Cover Stopper
- Plexiglass Front Panel

RS PRO Server Cabinets

RS Stock No.: 0749219



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

- *Areas of use: Offices (home, workplace), Branches (banks, government offices), Receptions (hotels, hospitals), Stores, markets, Residences (villas, apartments), Presentation and meeting rooms, Restaurants, cinemas*
- *Purposes of use: Compared to conventional cabinet-style solutions, it offers easier access, occupies less space, and adds prestige to the spaces where it is used with its more professional appearance.*

General Specifications

Rack Units	3U+5U
Type	Wall Mount
External Case Material	Steel
Base Material	Metal
Surface Finish	Electrostatic Powder Coating
Mounting	Wall type
Cabinet Size	Width: 535.00mm Depth: 400.00mm
Special Features	Drop Sticker Logo
Colour	RAL9005
Glass	Transparent-Solid
Ventilated	Yes
Fan Included	No
Adjustable Feet	No
EMC Shielding	No

Mechanical Specifications

External Dimensions	537.00mm x 475.00mm x 146.00mm
External Height	146.00mm
External Width	537.00mm
External Depth	475.00mm
Internal Depth	453.00mm
Weight	9.06 kg

Protection Category

IP Rating	IP20
-----------	------


Approvals

Declarations	MFR Declaration of Conformity
Standards Met	CE Marking / 2014/30/EU / 2014/35/EU / 2011/65/EU (RoHS II) / EN 61587-1 / EN IEC 60297 Series / EN IEC 60917 Series / EIA/ECA-310-D/E / EN IEC 62262


Accessories

Stock No.	Brand	Colour	Material	Mounting location in the cabin
0749246	RS PRO	RAL9005	Steel	19" Device Mounting Rails
0749247	RS PRO	RAL9005	Steel	19" Device Mounting Rails

Front View

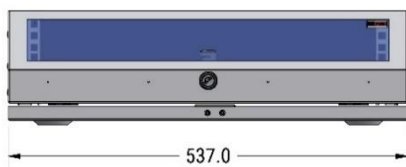


Side View

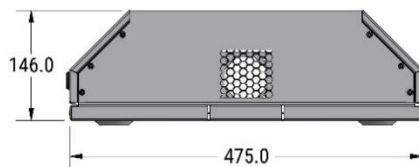


Rear View



Top View

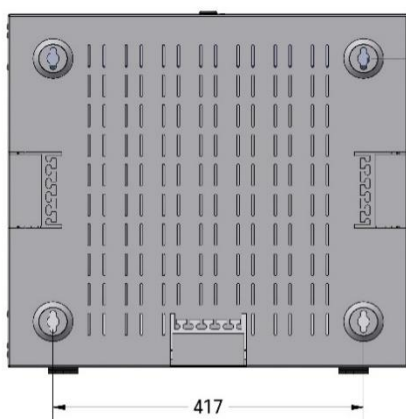

Bottom View

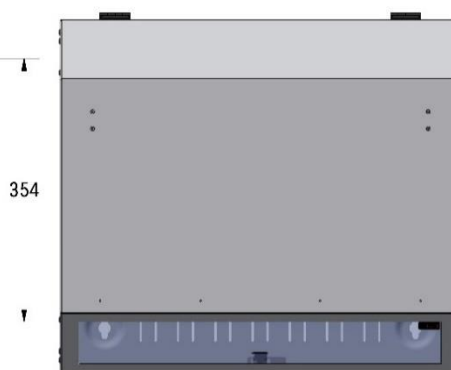

Front Isometric View

