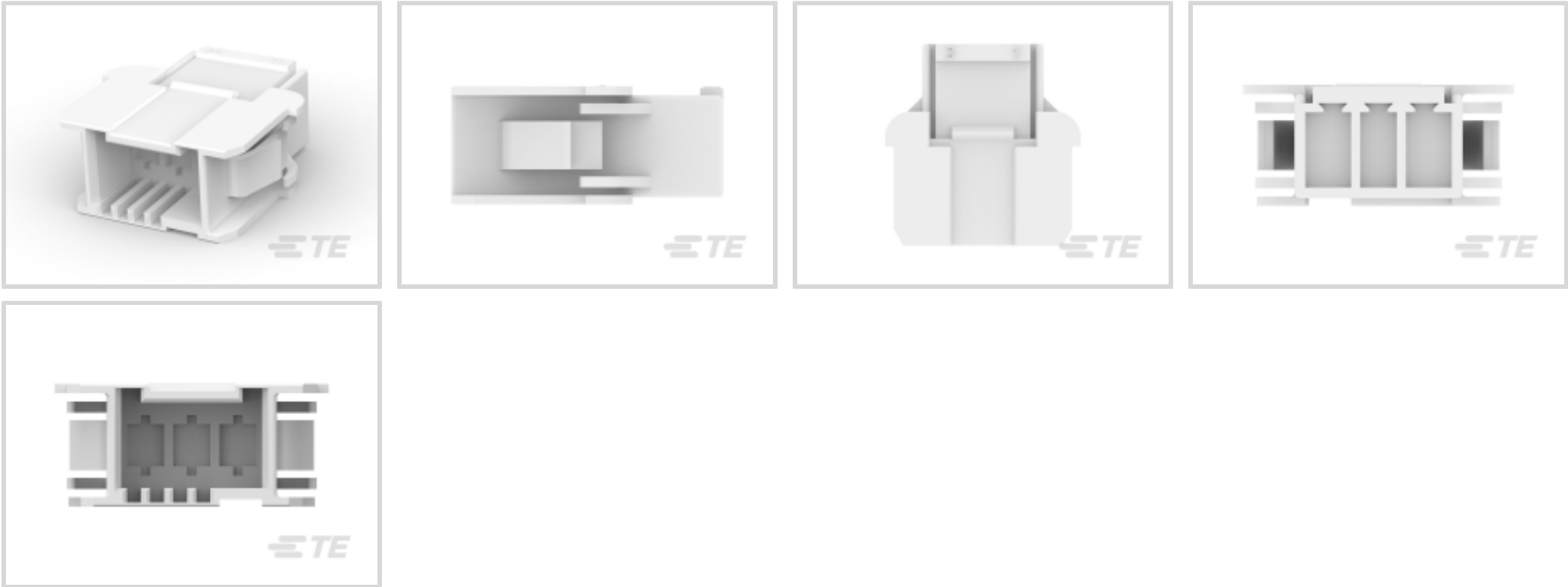




Terminals & Splices > Terminal Housings, Insulation Sleeves & Blocks > Crimp Terminal Housings



Terminal Type: **Tab**
Connector & Housing Type: **Tab Housing**
Number of Positions: **3**
Terminal Orientation: **Straight**
UL Flammability Rating: **UL 94V-2**

Features

Product Type Features

Connector & Contact Terminates To	Wire & Cable
Sealable	No
Connector & Housing Type	Tab Housing

Configuration Features

Number of Positions	3
---------------------	---

Body Features

Primary Product Color	Natural
-----------------------	---------

Contact Features

Terminal Type	Tab
Terminal Orientation	Straight
Contact Mating Retention	With

Mechanical Attachment

Mating Alignment	With
------------------	------



Connector Mounting Type	Panel Mount
Housing Features	
Housing Material	Polyamide
Centerline (Pitch)	5 mm[.196 in]
Dimensions	
Product Length	30.5 mm[1.2 in]
Usage Conditions	
Operating Temperature Range	-40 – 105 °C[-40 – 221 °F]
Industry Standards	
UL Flammability Rating	UL 94V-2
Packaging Features	
Packaging Quantity	200

Product Compliance

For compliance documentation, visit the product page on TE.com>













EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Not Low Halogen - contains Br or Cl > 900 ppm.
Solder Process Capability	Pin-in-Paste capable to 245°C

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>



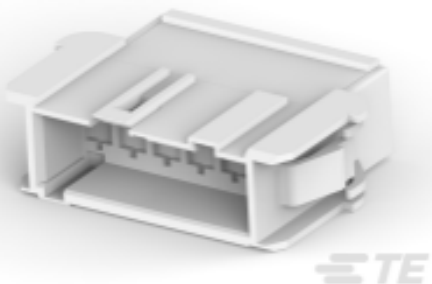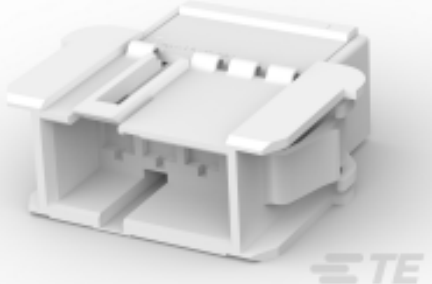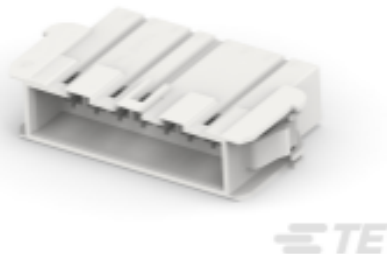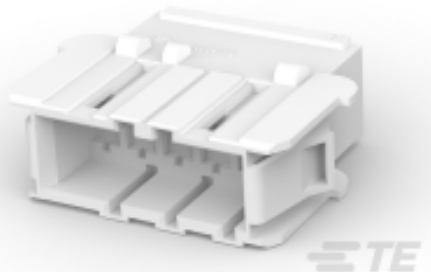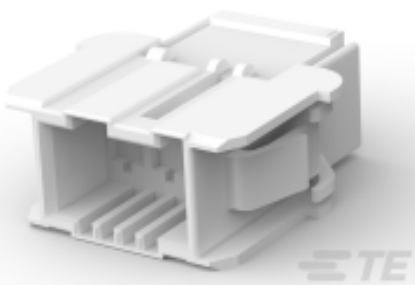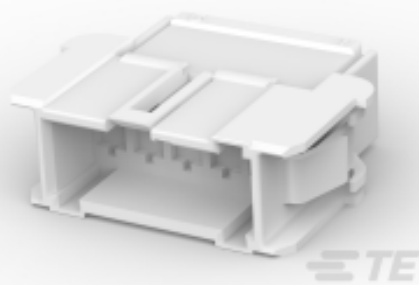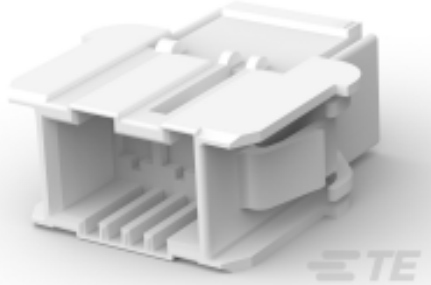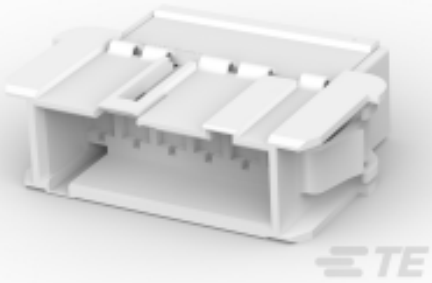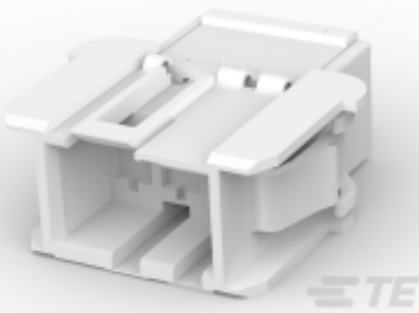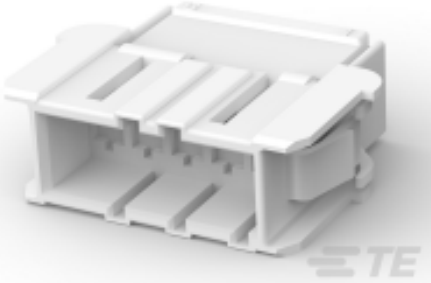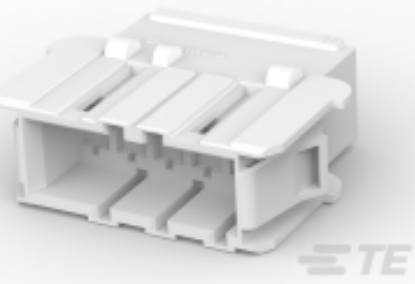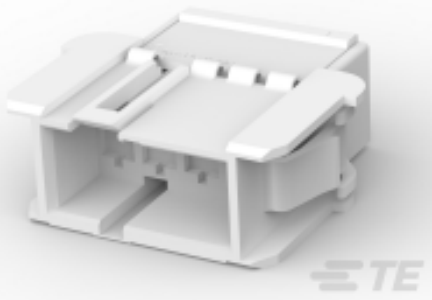Compatible Parts

 TE Part # 1-927742-6 6 POS. FASTIN-FASTON* TAB HSG RAST5	 TE Part # 9-927742-4 4POS FASTIN FASTON HOUSING	 TE Part # 1241969-8 FASTIN FASTON HOUSING 8P	 TE Part # 1241857-5 5 POS FASTIN/ON HOUSING PANEL MOUNT
 TE Part # 293008-1 3 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 5-293035-2 2 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 293011-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R	 TE Part # 293008-3 3 POS. FASTIN-FASTON CONN. TAB HOUSING R
 TE Part # 7-927742-6 6 POS. FASTIN-FASTON* TAB HSG RAST5	 TE Part # 1-1241968-5 FASTIN FASTON HOUSING 10P	 TE Part # 9-927742-3 FASTIN FASTON HOUSING 3POS	 TE Part # 293010-1 5 POS. FASTIN-FASTON CONN. TAB HOUSING R
 TE Part # 9-1241857-5 5POS. FASTIN-FASTON* TAB HSG, RAST5	 TE Part # 927742-4 4 POS FASTIN/ON HOUSING PANEL MOUNT		

Also in the Series | RAST 5 IDC Connectors



Connector Contacts(12)



Crimp Terminal Housings(39)



Insertion & Extraction Tools(1)



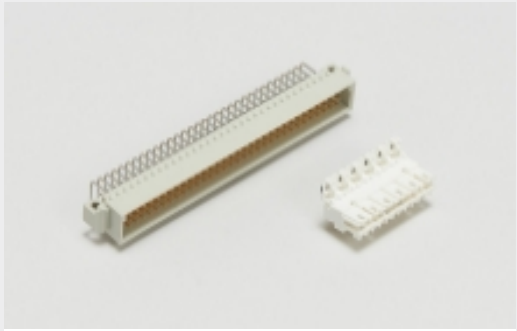
PCB Headers & Receptacles(417)



Power Contacts(3)



Rectangular Power Connectors(481)




Standard Edge Connectors(31)



Wire-to-Board Headers & Receptacles (417)

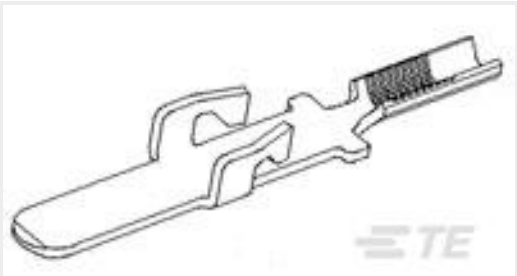Customers Also Bought



TE Part #1217073-1
CONT AMVAR 125 BLADE 020 TPBR



TE Part #42037-1
RING TERMINAL 22-18 AWG TPBR



TE Part #293011-1
5 POS. FASTIN-FASTON CONN. TAB HOUSING R



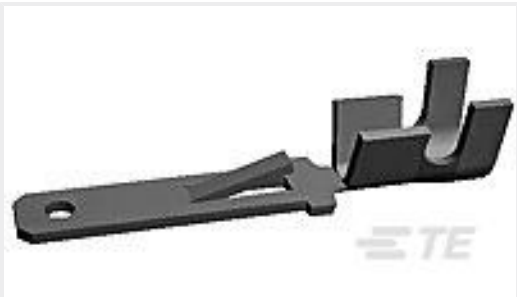
TE Part #1217071-1
CONTACT, BLADE 125 20-16 AWG TPBR




TE Part #1971784-2
PTL TAB CONTACT, 16-19 AWG, 2X22 AWG




TE Part #1241857-5
5 POS FASTIN/ON HOUSING PANEL MOUNT



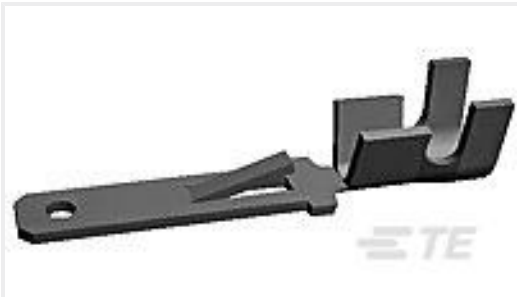TE Part #62553-3
FF 250 TAB 22-18AWG TPBR



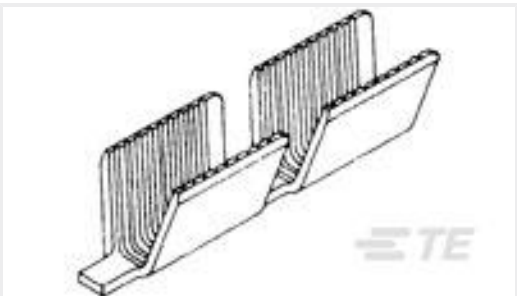TE Part #293041-2
FF 250 TAB 0.35-1.0MM2 TPBR



TE Part #62306-2
AMVAR SPLC 1500-5000 020TPBR



TE Part #2-1971777-4
PTL TPA HWI 1X4 NATURAL

Documents



Product Drawings

3 POS. FASTIN-FASTON CONNECTOR TAB HOUSI

English

CAD Files

Customer View Model

ENG_CVM_CVM_1955416-1_A.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1955416-1_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1955416-1_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

RAST Connector System Catalog

English

Product Specifications

Product Specification

English

Agency Approvals

VDE Certificate

English